




TOP VIEW

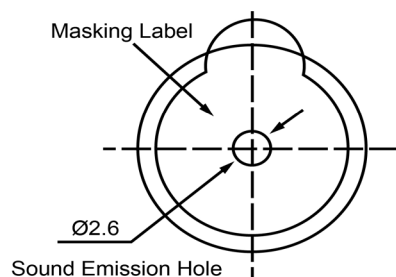


SIDE VIEW

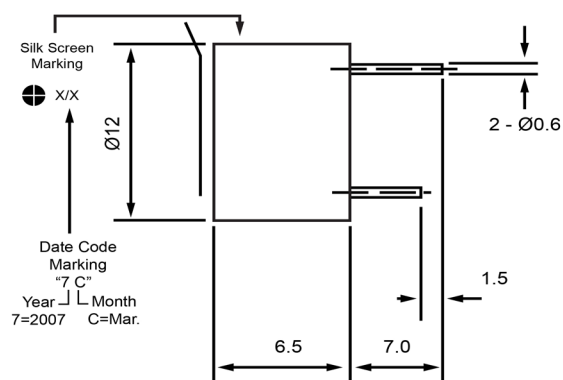

BOTTOM VIEW

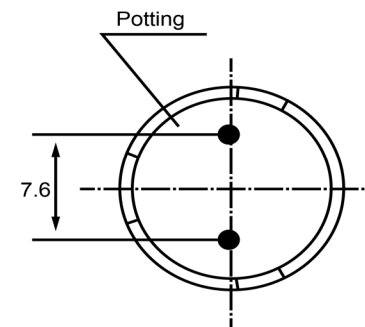

| Specifications        |                    |       | Notes  | Revision History |                           |  |            |          |  |
|-----------------------|--------------------|-------|--|------------------|---------------------------|--|------------|----------|--|
| Description           | Value              | Unit  |  | Version          | Description               |  | Date       | Approved |  |
| Technology            | Electro-Mechanical |       | 1) All dimensions are in mm unless otherwise noted<br>2) All parts meet RoHS | 1                | Released from Engineering |  | 10/21/2013 | J.S      |  |
| Resonant Frequency    | 2,300              | (Hz)  |  |                  |                           |  |            |          |  |
| Rated Voltage         | 5                  | (V)   |  |                  |                           |  |            |          |  |
| SPL @ 10cm            | 85                 | (dBA) |  |                  |                           |  |            |          |  |
| Tone                  | Single Tone        |       |  |                  |                           |  |            |          |  |
| Mount Type            | Thru Hole          |       |  |                  |                           |  |            |          |  |
| Voltage Range         | 4 ~ 7              | (V)   |  |                  |                           |  |            |          |  |
| Max Rated Current     | 30                 | (mA)  |  |                  |                           |  |            |          |  |
| Housing Material      | NORYL              |       |  |                  |                           |  |            |          |  |
| Operating Temperature | -20 ~ +70          | °C    |  |                  |                           |  |            |          |  |
| Storage Temperature   | -20 ~ +70          | °C    |  |                  |                           |  |            |          |  |
| Weight                | 2                  | (g)   |  |                  |                           |  |            |          |  |



DB UNLIMITED

Electro-Mechanical Indicator

IE122305-1

| Drawn by | Date       | Checked by | Date       | Approved by | Date       |
|----------|------------|------------|------------|-------------|------------|
| A.B.     | 10/21/2013 | C.E.       | 10/21/2013 | J.S         | 10/21/2013 |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE122305-1](#)