






DB UNLIMITED

Part Number:	1	
	DRAWN	8/13/2021
	CJ	
Description:	8/13/2021	
	CHECKED	
	P.D.	
Electro-Mechanical Indicator	8/13/2021	
	APPROVED	
	J.S.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		

Top View

Side View

Bottom View

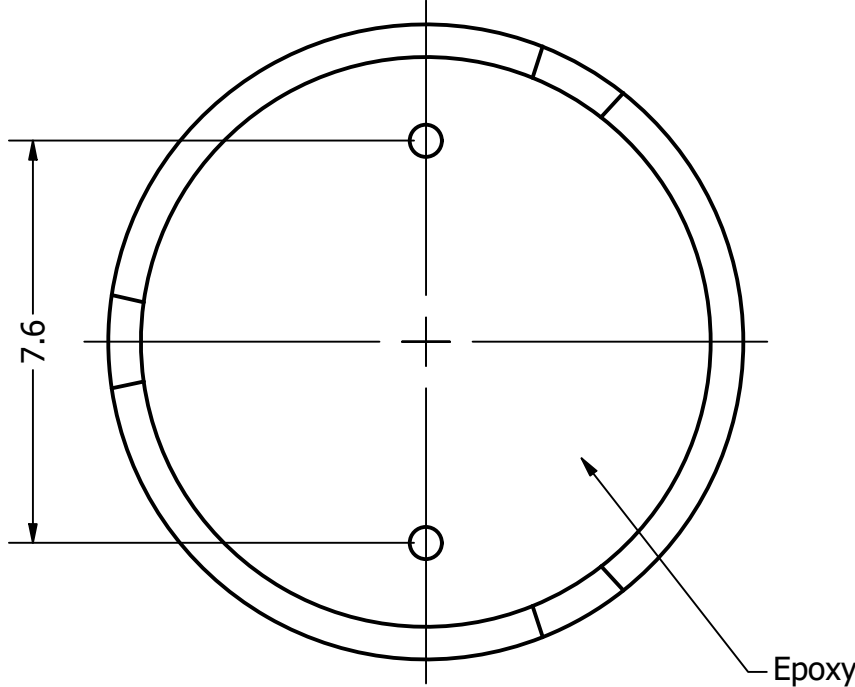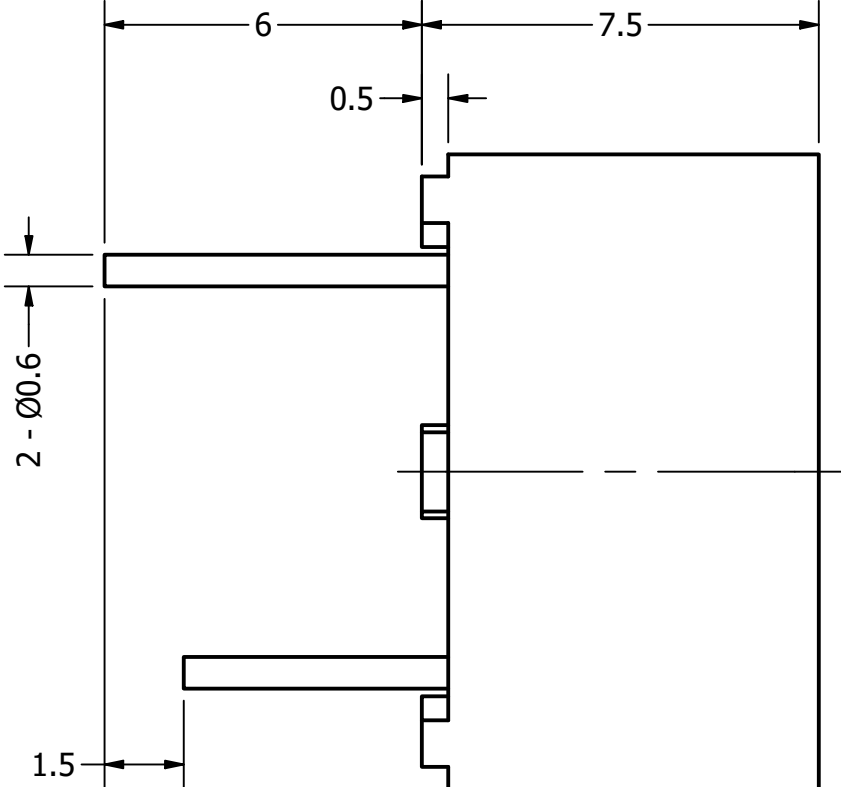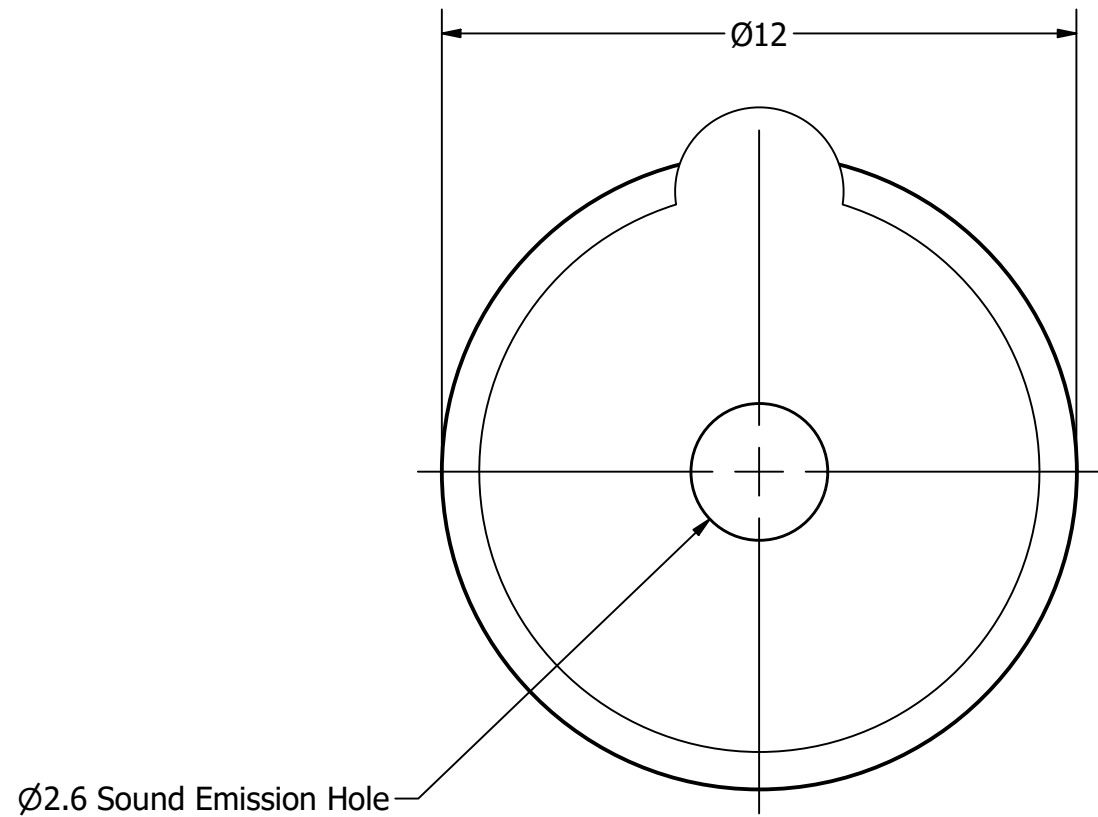

Items	Specifications	Conditions				
Min. Sound Pressure Level	83	dB (@ 10cm)				
Tone	Single					
Resonant Frequency	2,300	Hz	REVISION HISTORY			
Rated Voltage	5	V	REV	DESCRIPTION	DATE	APPROVED
Voltage Range	3 ~ 6.5	V		Released from Engineering	10/21/2013	J.S.
Max. Rated Current	30	mA	1	Updated drawing template, housing material, voltage range	8/13/2021	P.D.
Storage Temperature	-20 ~ +70	°C				
Operating Temperature	-20 ~ +70	°C	NOTES			
Connection Method	PC Pins		1) All dimensions are in mm unless otherwise noted			
Mount Type	Thru Hole		2) All tolerances are ± 0.5 mm unless otherwise noted			
Housing Material	PBT		3) All parts meet RoHS			
Weight	2	g	4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE122305-2](#)