




TOP VIEW

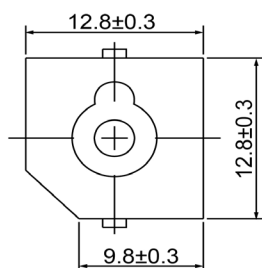


SIDE VIEW (1)

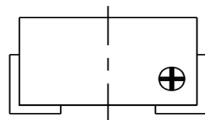

SIDE VIEW (2)

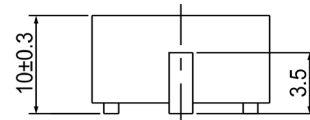

BOTTOM VIEW

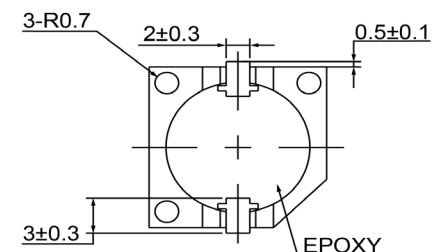

## Specifications

Description	Value	Unit
Technology	Electro-Mechanical	
Resonant Frequency	2,400	(Hz)
Rated Voltage	1.5	(V)
SPL @ 10cm	80	(dBA)
Tone	Single	
Mount Type	Surface Mount	
Voltage Range	1 ~ 3	(V)
Max Rated Current	20	(mA)
Housing Material	PPS	
Operating Temperature	-30 ~ +70	°C
Storage Temperature	-40 ~ +85	°C
Weight	2	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted  
 2) All parts meet RoHS



Electro-Mechanical Indicator

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

IE122401-1

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

DB Unlimited:

[IE122401-1](#) [IE122305-4](#)