




TOP VIEW

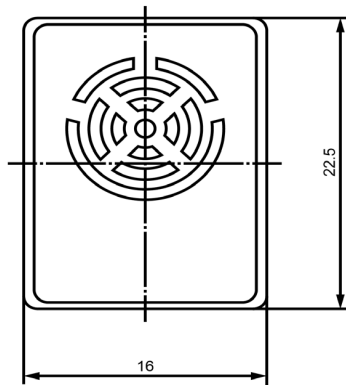


SIDE VIEW

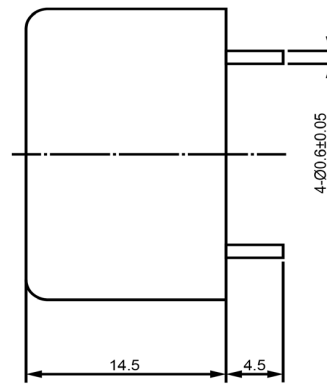

BOTTOM VIEW

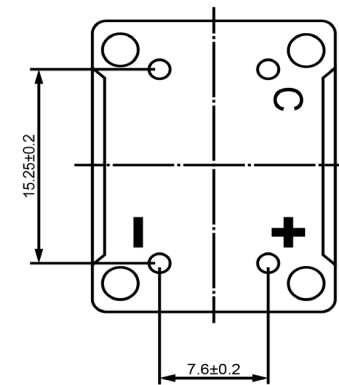

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description			Date	Approved
Technology	Electro-Mechanical		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering			10/21/2013	J.S
Resonant Frequency	400	(Hz)							
Rated Voltage	12	(V)							
SPL @ 10cm	81	(dBA)							
Tone	Single								
Mount Type	Thru Hole								
Voltage Range	9 ~ 15	(V)							
Max Rated Current	25	(mA)							
Housing Material	NORYL								
Operating Temperature	-30 ~ +70	°C							
Storage Temperature	-40 ~ +85	°C							
Weight	10	(g)							
 DB UNLIMITED			Electro-Mechanical Indicator			IE220412-1			

Additional considerations can be found at [www.dbunlimitedco.com/technical-articles](http://www.dbunlimitedco.com/technical-articles).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE220412-1](#)