





DB UNLIMITED

Part Number: IE220424-1	DRAWN CJ	12/12/2018
	CHECKED C.H.	12/12/2018
	APPROVED C.E.	12/12/2018
Description: Electro-Mechanical Transducer		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

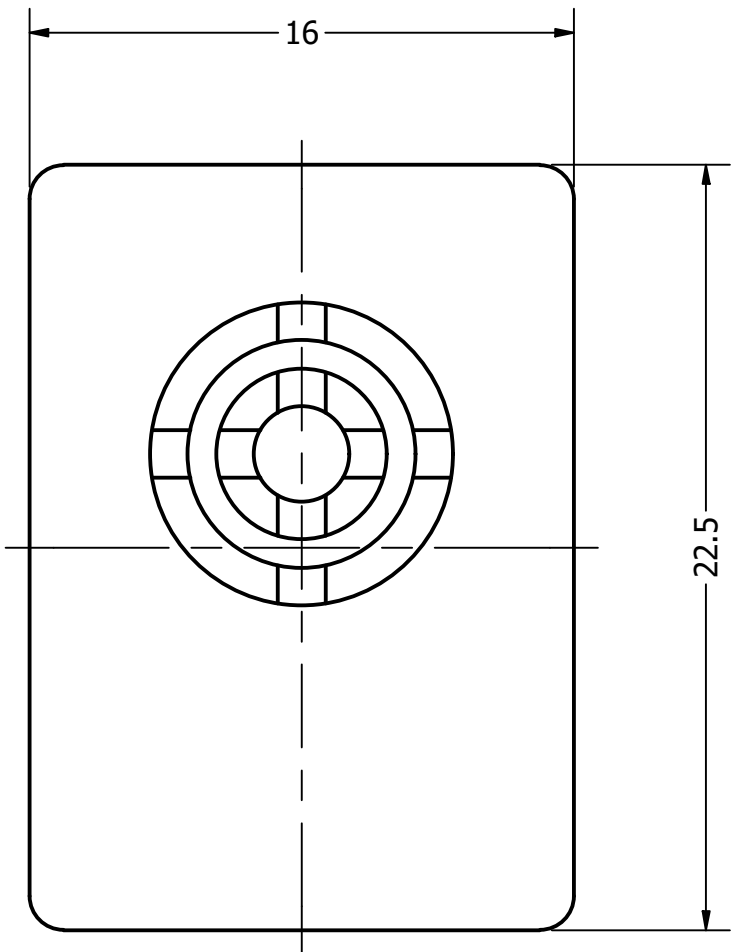

Side View

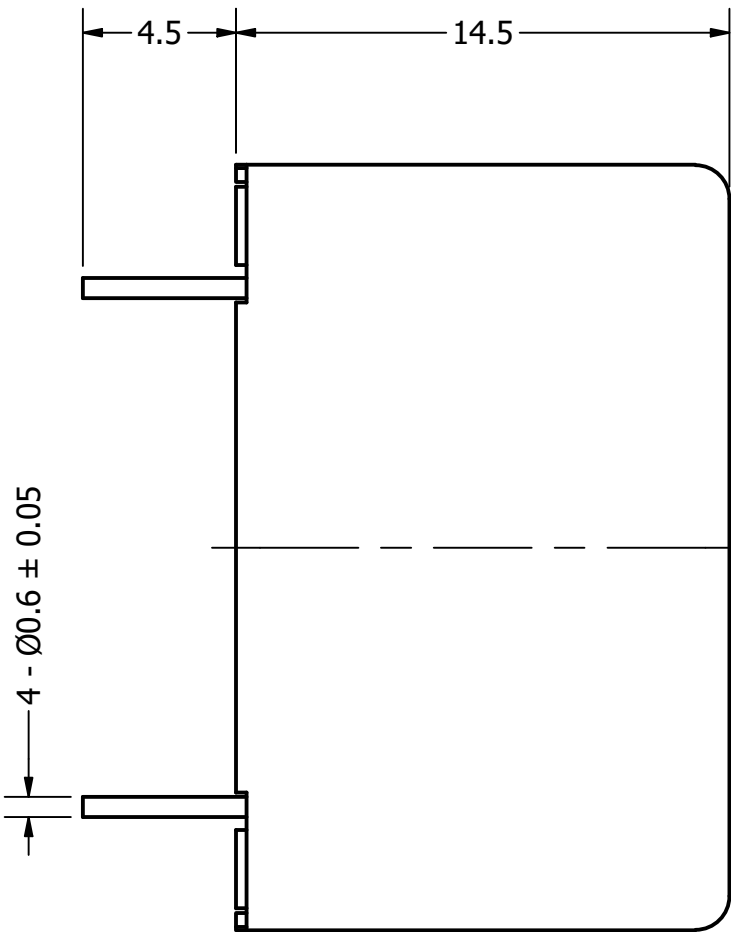

Bottom View

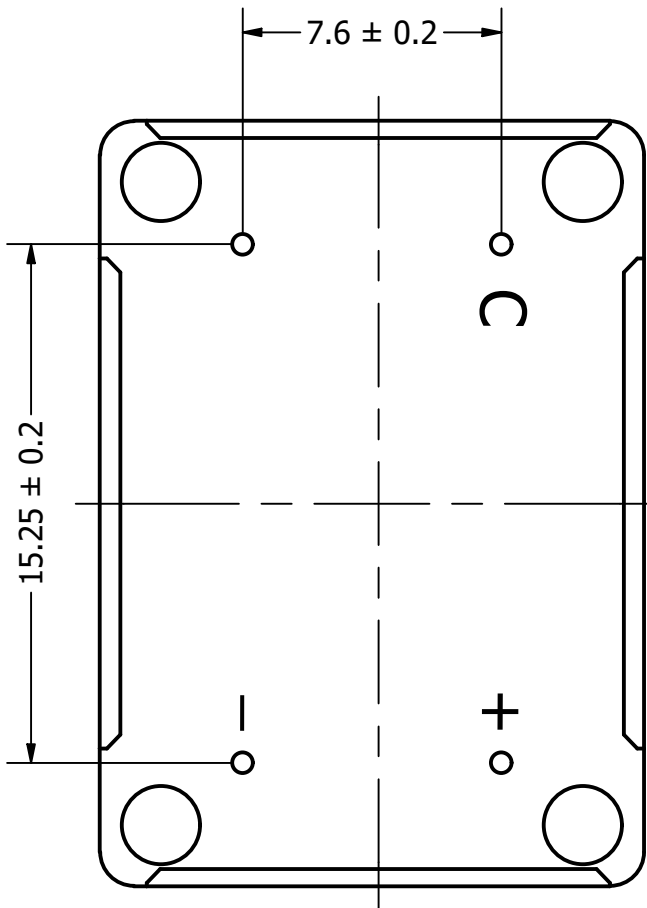

Items	Specifications	Conditions				
Min. Sound Pressure Level	81	dB (@ 10cm)				
Resonant Frequency	400	Hz				
Rated Voltage	24	V	REV	DESCRIPTION	DATE	APPROVED
Voltage Range	15 ~ 27	V		Released from Engineering	10/21/2013	J.S.
Max. Rated Current	30	mA	1	Updated to new template	12/12/2018	C.E.
Storage Temperature	-40 ~ +85	°C				
Operating Temperature	-30 ~ +70	°C				
Connection Method	PC Pins					
Mount Type	Thru-Hole					
Housing Material	NORYL					
Weight	10	g				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE220424-1](#)