



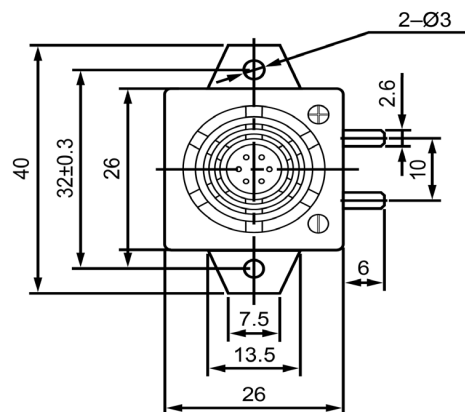

TOP VIEW

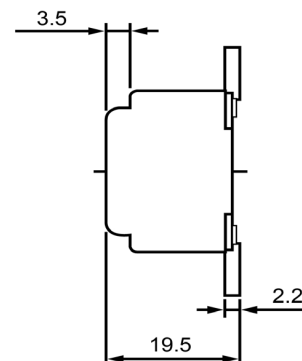

SIDE VIEW



Specifications			Notes	Revision History								
Description	Value	Unit		Version	Description		Date	Approved				
Technology	Electro-Mechanical		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S				
Resonant Frequency	400	(Hz)										
Rated Voltage	6	(V)										
SPL @ 10cm	95	(dBA)										
Tone	Single											
Mount Type	Flange Mount											
Voltage Range	4 ~ 8	(V)										
Max Rated Current	65	(mA)										
Housing Material	ABS											
Operating Temperature	-20 ~ +60	°C										
Storage Temperature	-30 ~ +70	°C										
Weight	17	(g)										
						Drawn by		Date	Checked by	Date	Approved by	Date
						A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			Electro-Mechanical Indicator			IE260406-2						

Additional considerations can be found at [www.dbunlimitedco.com/technical-articles](http://www.dbunlimitedco.com/technical-articles).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE260406-2](#)