



Part Number:	IE320425-1	DRAWN	5/20/2019
		CJ	
Description:	Electro-Mechanical Indicator	CHECKED	5/28/2019
		C.H.	
		APPROVED	5/28/2019
		C.E.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com			


Top View

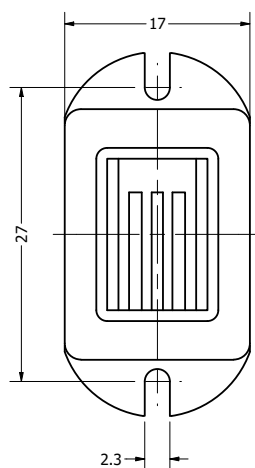

Side View

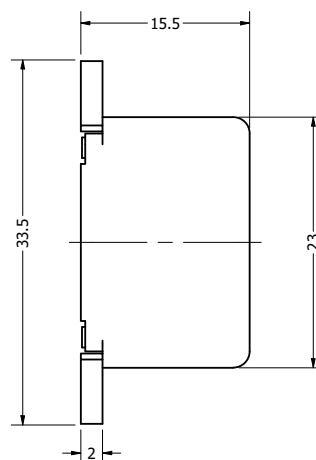

Bottom View

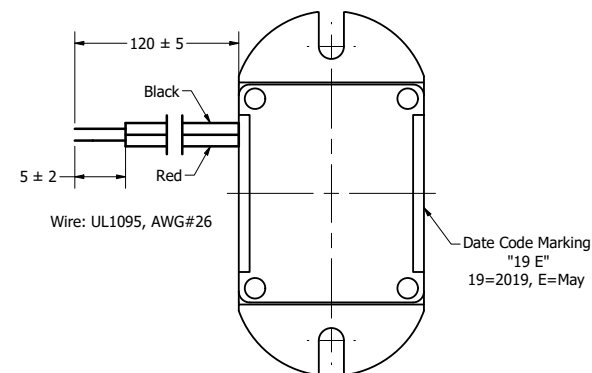

Items	Specifications	Conditions				
Min. Sound Pressure Level	81	dB (@ 10cm)				
Tone	Single					
Resonant Frequency	400	Hz				
Rated Voltage	24	V				
Voltage Range	15 ~ 27	V				
Max. Rated Current	30	mA				
Storage Temperature	-20 ~ +70	°C				
Operating Temperature	-20 ~ +70	°C				
Connection Method	Lead Wires					
Mount Type	Flange Mount					
Housing Material	ABS					
Weight	8	g				
			REVISION HISTORY			
			REV	DESCRIPTION	DATE	APPROVED
				Released from Engineering	10/21/2013	J.S.
			1	Updated drawing template, length, SPL, temps, weight	5/28/2019	C.E.
			NOTES			
			1) All dimensions are in mm unless otherwise noted			
			2) All tolerances are ± 0.5 mm unless otherwise noted			
			3) All parts meet RoHS			
			4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE320425-1](#)