





DB UNLIMITED

Part Number:	DRAWN CJ	5/20/2019
IP2333220-1	CHECKED	5/21/2019
	C.H.	
Description:	APPROVED	5/21/2019
	C.E.	
Piezo Indicator		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

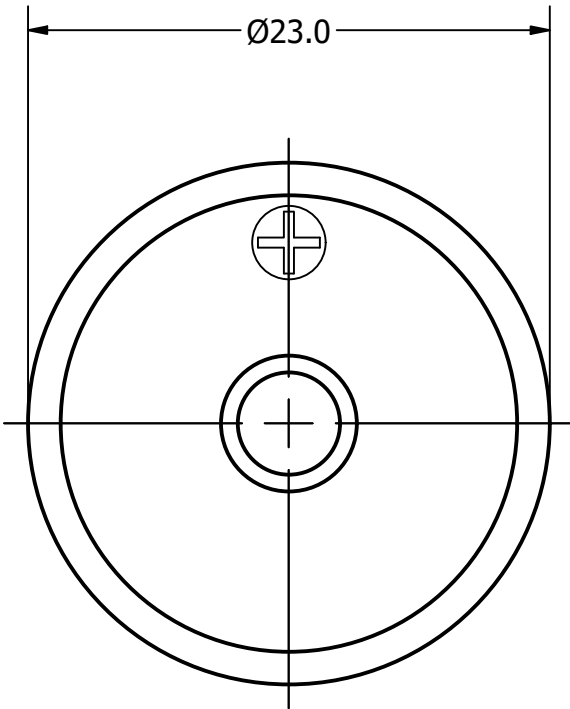

Side View

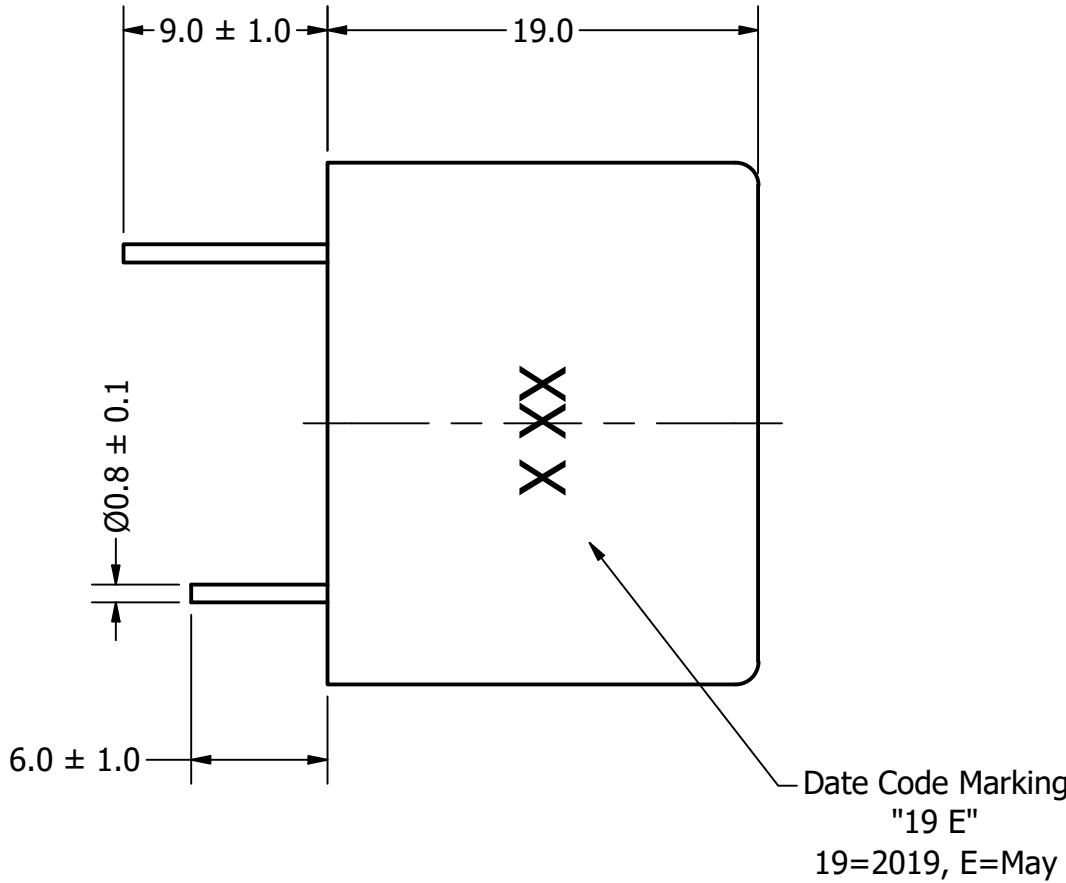

Bottom View

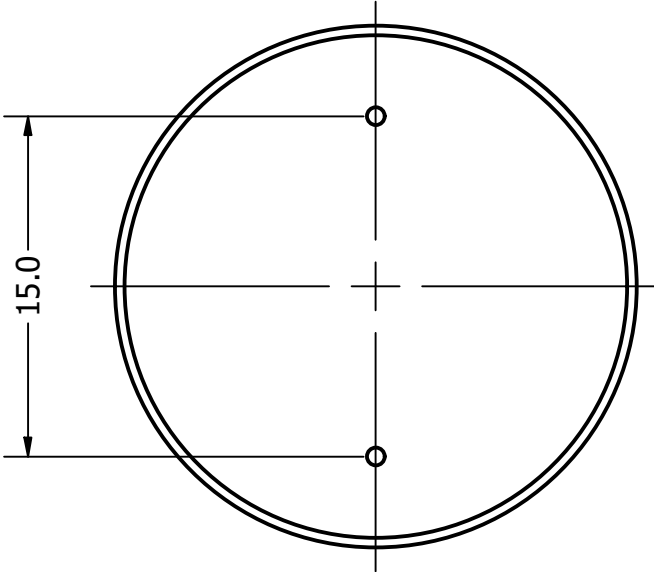

Items	Specifications	Conditions				
Min. Sound Pressure Level	90	dB (@ 10cm)				
Tone	Single					
Resonant Frequency	3,300	Hz				
Rated Voltage	220	VAC				
Voltage Range	30 ~ 264	VAC				
Max. Rated Current	5	mA				
Storage Temperature	-30 ~ +70	°C				
Operating Temperature	-20 ~ +60	°C				
Connection Method	PC Pins					
Mount Type	Thru Hole					
Housing Material	ABS					
Weight	8	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	10/21/2013	J.S.
1	Updated drawing template, pin length tolerance	5/21/2019	C.E.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP2333220-1](#)