





DB UNLIMITED

Part Number:	DRAWN	10/21/2013
	A.B.	
	CHECKED	10/21/2013
Description:	C.E.	
	APPROVED	10/21/2013
Piezo Indicator		J.S.
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

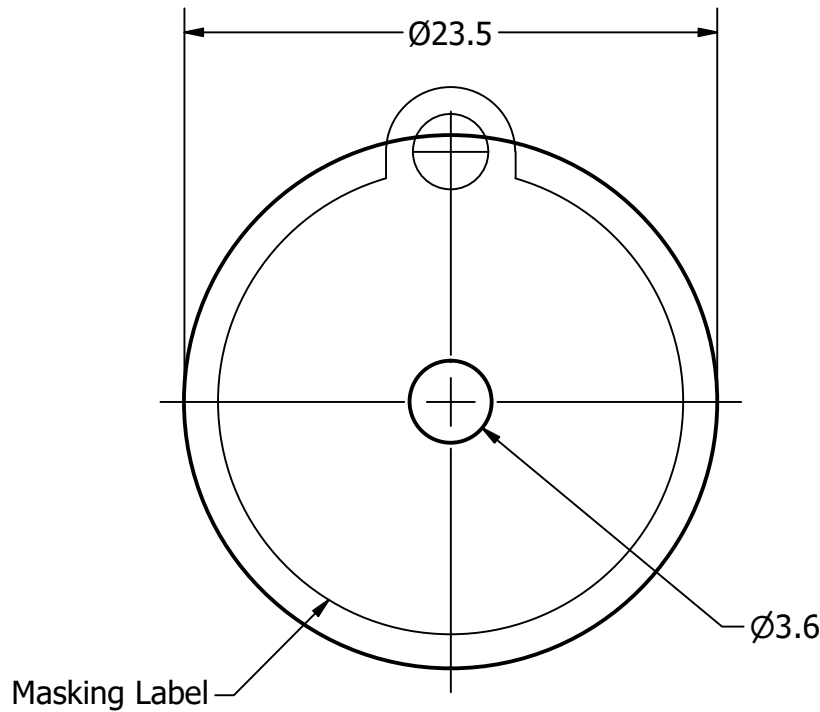

Side View

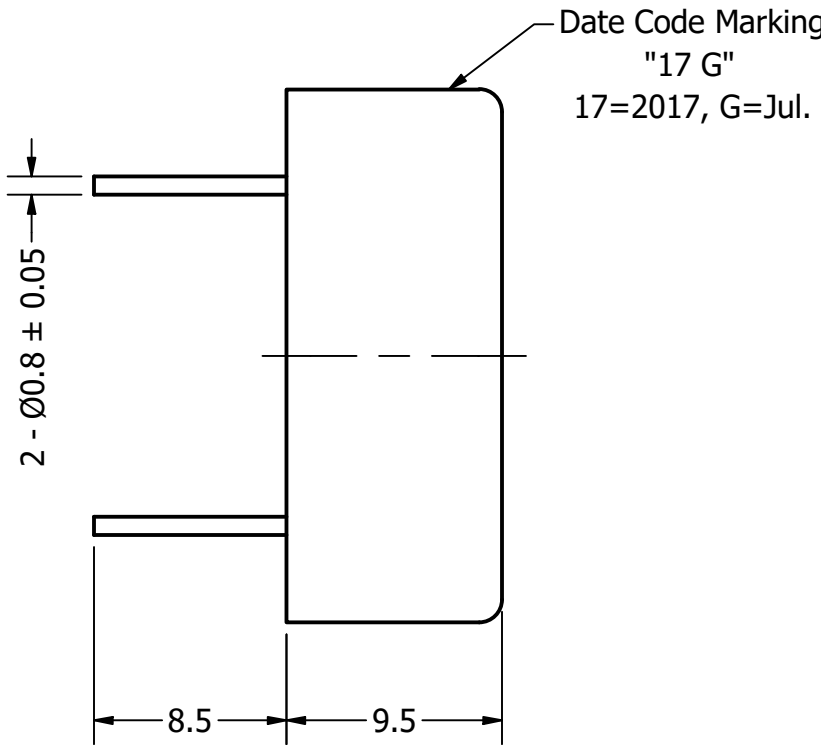

Bottom View

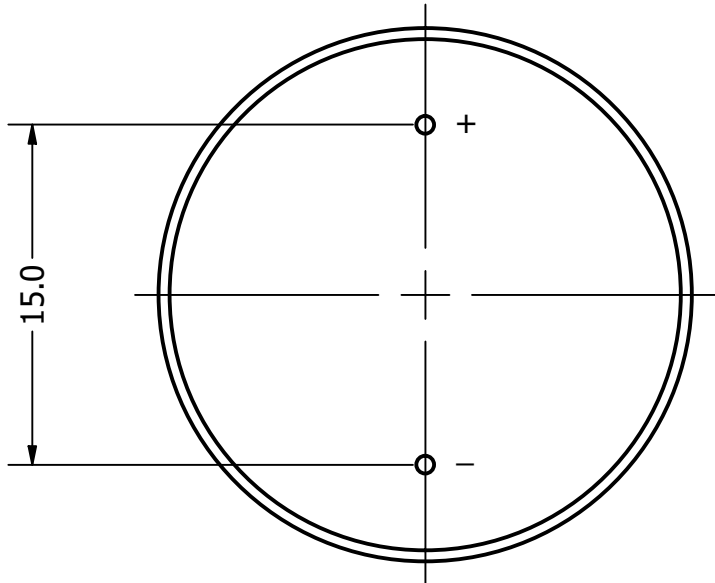

Items	Specifications	Conditions				
Sound Pressure Level	90	dB (@ 10cm)				
Tone	Single					
Resonant Frequency	3,400 ± 400	Hz	REVISION HISTORY			
Rated Voltage	12	V	REV	DESCRIPTION	DATE	APPROVED
Voltage Range	3 ~ 20	V		Released from Engineering	10/21/2013	J.S.
Max. Rated Current	8	mA	1	Show washtab, update temps, update to new template	7/5/2017	C.E.
Storage Temperature	-40 ~ +85	°C	2	Updated current, storage temperature	9/27/2024	P.D.
Operating Temperature	-30 ~ +85	°C	NOTES			
Connection Method	PC Pins		1) All dimensions are in mm unless otherwise noted			
Mount Type	Thru Hole		2) All tolerances are ± 0.5 mm unless otherwise noted			
Housing Material	Noryl		3) All parts meet RoHS			
Weight	4	g	4) Subject to change or redrawn without notice			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP233412-1](#)