




TOP VIEW

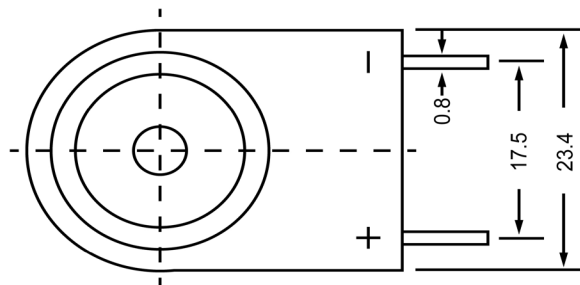

SIDE VIEW

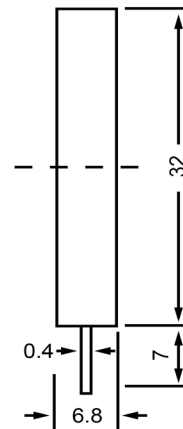

| Specifications | | | Notes | Revision History | | | | | |
|-----------------------|-----------|-------|--|------------------|---------------------------|--------------------|--------------------|--------------------|--------------------|
| Description | Value | Unit | | Version | Description | Date | Approved | | |
| Technology | Piezo | | 1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS | 1 | Released from Engineering | 10/21/2013 | J.S | | |
| Resonant Frequency | 5,800 | (Hz) | | | | | | | |
| Rated Voltage | 12 | (V) | | | | | | | |
| SPL @ 10cm | 85 | (dBA) | | | | | | | |
| Tone | Single | | | | | | | | |
| Mount Type | Thru-hole | | | | | | | | |
| Voltage Range | 3 ~ 24 | (V) | | | | | | | |
| Max Rated Current | 8 | (mA) | | | | | | | |
| Housing Material | ABS | | | | | | | | |
| Operating Temperature | -20 ~ +60 | °C | | | | | | | |
| Storage Temperature | -20 ~ +60 | °C |  | Drawn by A.B. | Date 10/21/2013 | Checked by C.E. | Date 10/21/2013 | Approved by J.S | Date 10/21/2013 |
| Weight | 8 | (g) | | Piezo Indicator | | | IP235812-1 | | |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP235812-1](#)