




TOP VIEW

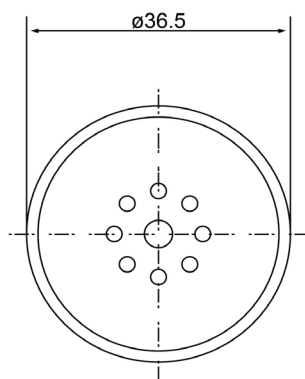


NUT

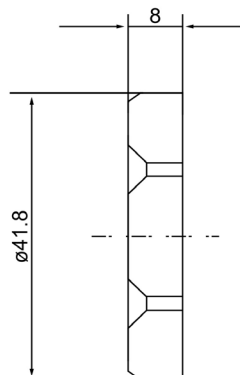

SIDE VIEW

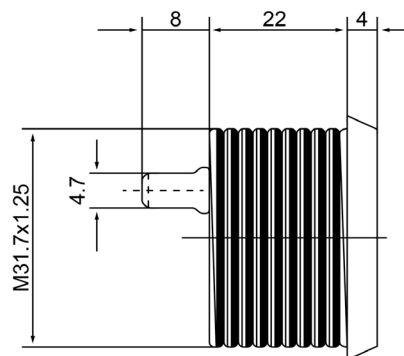

BOTTOM VIEW

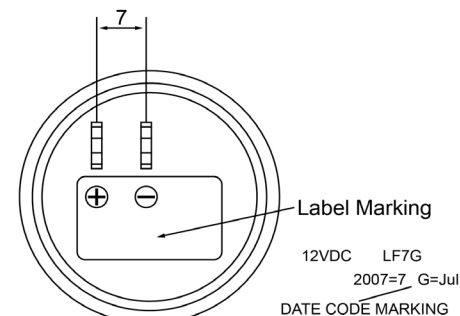

Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	3,000	(Hz)
Rated Voltage	12	(V)
SPL @ 10cm	85	(dBA)
Tone	Fast Pulse	
Mount Type	Panel	
Voltage Range	5 ~ 28	(V)
Max Rated Current	18	(mA)
Housing Material	ABS	
Operating Temperature	-20 ~ +60	°C
Storage Temperature	-30 ~ +70	°C
Weight	35	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
2) All parts meet RoHS



DB UNLIMITED

Piezo Indicator

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

IP363012-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP363012-1](#)