




TOP VIEW

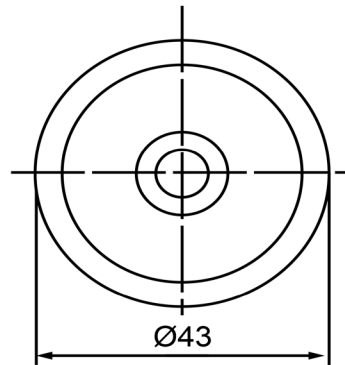

SIDE VIEW

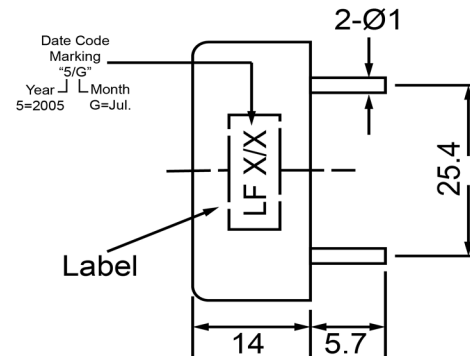

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	2,800	(Hz)								
Rated Voltage	12	(V)								
SPL @ 10cm	110	(dBA)								
Tone	Single									
Mount Type	Thru-hole									
Voltage Range	3 ~ 20	(V)								
Max Rated Current	12	(mA)								
Housing Material	ABS									
Operating Temperature	-20 ~ +60	°C								
Storage Temperature	-20 ~ +60	°C								
Weight	11	(g)								
 DB UNLIMITED			Piezo Indicator			Revision History				
						IP432812-1				
						Drawn by		Date	Checked by	Date
			A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP432812-1](#)