




TOP VIEW

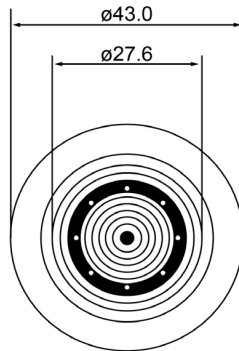


NUT

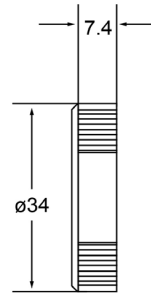


SIDE VIEW

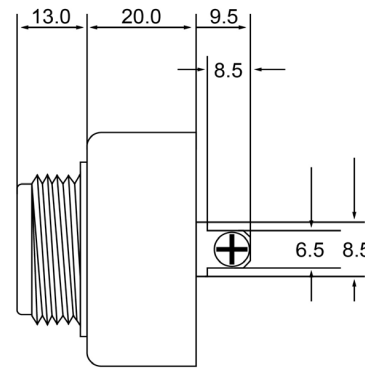

BOTTOM VIEW

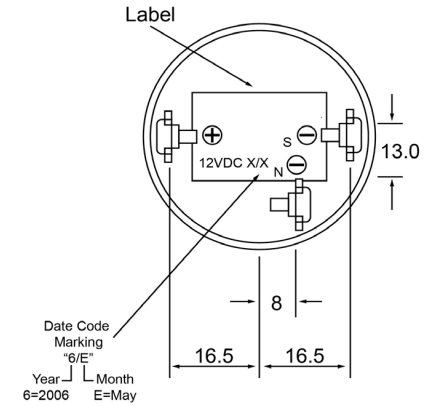

| Specifications | | | Notes | Revision History | | | | | |
|-----------------------|------------|-------|---|------------------|---------------------------|------------|------------|-------------|------------|
| Description | Value | Unit | | Version | Description | | Date | Approved | |
| Technology | Piezo | | 1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS | 1 | Released from Engineering | | 10/21/2013 | J.S | |
| Resonant Frequency | 2,900 | (Hz) | | | | | | | |
| Rated Voltage | 12 | (V) | | | | | | | |
| SPL @ 10cm | 100 | (dBA) | | | | | | | |
| Tone | Slow Pulse | | | | | | | | |
| Mount Type | Panel | | | | | | | | |
| Voltage Range | 6 ~ 28 | (V) | | | | | | | |
| Max Rated Current | 20 | (mA) | | | | | | | |
| Housing Material | ABS | | | | | | | | |
| Operating Temperature | -20 ~ +60 | °C | | | | | | | |
| Storage Temperature | -30 ~ +70 | °C | | | | | | | |
| Weight | 35 | (g) | | | | | | | |
| | | |  DB UNLIMITED | Piezo Indicator | | | IP432912-1 | | |
| | | | | | | | | | |
| | | | | Drawn by | Date | Checked by | Date | Approved by | Date |
| | | | | A.B. | 10/21/2013 | C.E. | 10/21/2013 | J.S | 10/21/2013 |

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP432912-1](#)