




TOP VIEW

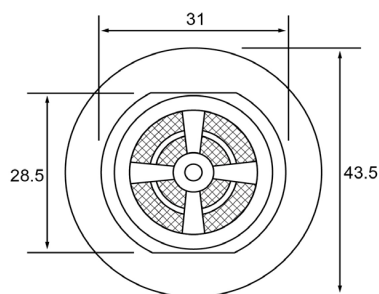


SIDE VIEW

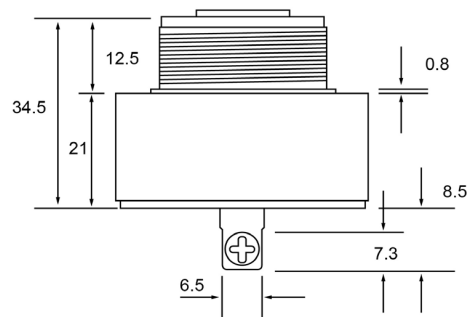

NUT

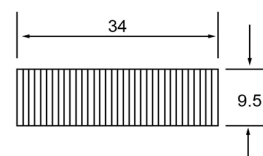

BOTTOM VIEW

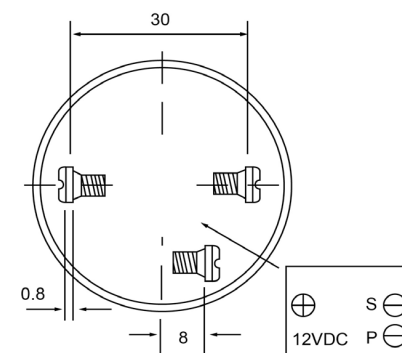

## Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	2,900	(Hz)
Rated Voltage	12	(V)
SPL @ 10cm	100	(dBA)
Tone	Dual Tone	
Mount Type	Panel	
Voltage Range	4 ~ 16	(V)
Max Rated Current	20/25	(mA)
Housing Material	ABS	
Operating Temperature	-20 ~ +60	°C
Storage Temperature	-30 ~ +70	°C
Weight	35	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Piezo Indicator

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
	</				

IP432912-2

Additional considerations can be found at [www.dbunlimitedco.com/technical-articles](http://www.dbunlimitedco.com/technical-articles).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP432912-2](#)