




TOP VIEW

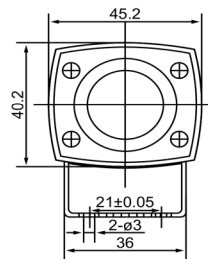

SIDE VIEW

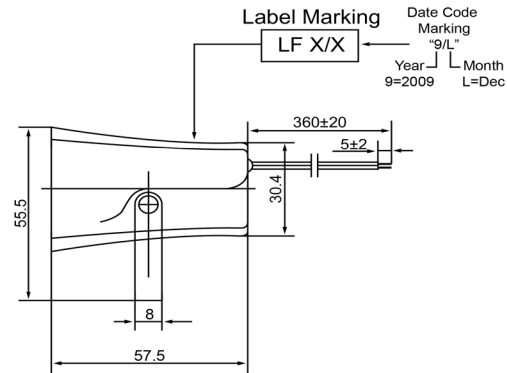

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S	
Resonant Frequency	3,500	(Hz)							
Rated Voltage	24	(V)							
SPL @ 10cm	100	(dBA)							
Tone	Siren								
Mount Type	Bracket								
Voltage Range	12 ~ 28	(V)							
Max Rated Current	150	(mA)							
Housing Material	ABS								
Operating Temperature	-20 ~ +60	°C							
Storage Temperature	-30 ~ +70	°C							
Weight	75	(g)							
 DB UNLIMITED			Piezo Indicator			IP441024-1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP441024-1](#)