




TOP VIEW

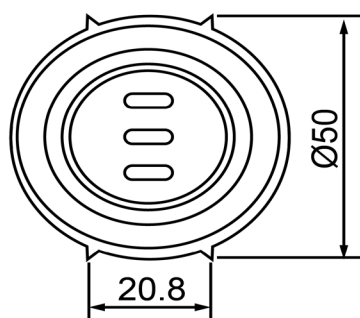




SIDE VIEW

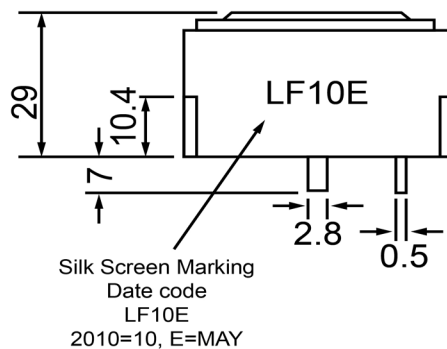

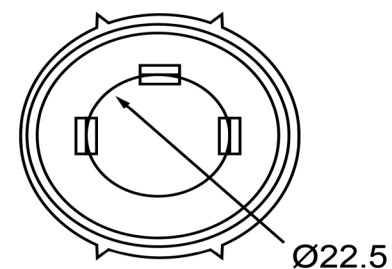BOTTOM VIEW

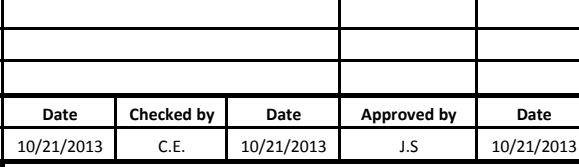

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	2,500	(Hz)								
Rated Voltage	12	(V)								
SPL @ 10cm	115	(dBA)								
Tone	Single									
Mount Type	Thru-hole									
Voltage Range	3 ~ 13	(V)								
Max Rated Current	75	(mA)								
Housing Material	ABS									
Operating Temperature	-20 ~ +60	°C								
Storage Temperature	-20 ~ +60	°C								
Weight	40	(g)								
 DB UNLIMITED										
			Piezo Indicator		IP502512-1					

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP502512-1](#)