




TOP VIEW

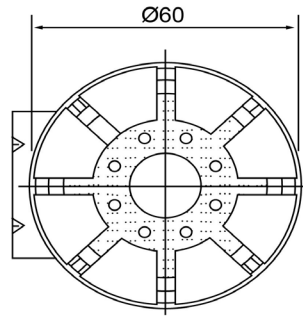

SIDE VIEW

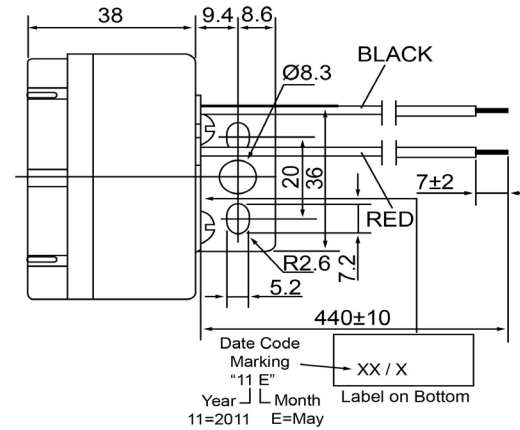

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	2,800	(Hz)								
Rated Voltage	12	(V)								
SPL @ 10cm	120	(dBA)								
Tone	Single									
Mount Type	Flange									
Voltage Range	6 ~ 15	(V)								
Max Rated Current	300	(mA)								
Housing Material	ABS									
Operating Temperature	-20 ~ +70	°C								
Storage Temperature	-20 ~ +70	°C		Drawn by		Date	Checked by	Date	Approved by	Date
Weight	110	(g)		A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			DB UNLIMITED	Piezo Indicator			IP602812-1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IP602812-1](#)