





Part Number:	MM033802-7	
	DESCRIPTION	ANALOG MEMS MICROPHONE
DRAWN	CJ	7/25/2018
	CHECKED	C.H.
APPROVED	C.H.	8/16/2018
	C.E.	8/16/2018
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

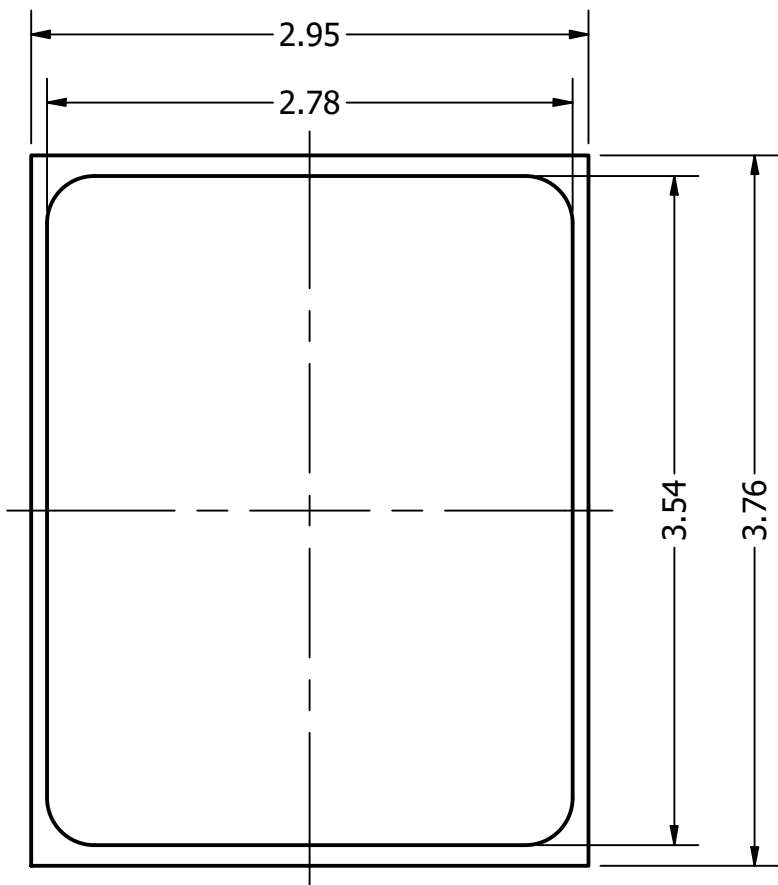

Side View

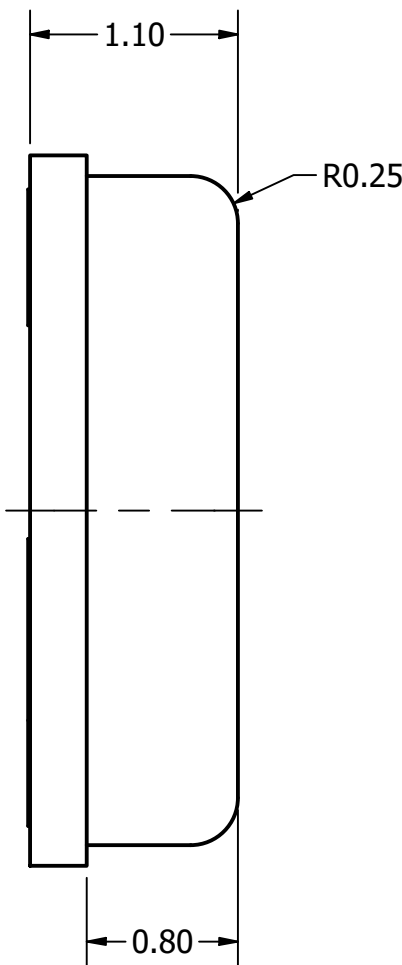

Bottom View

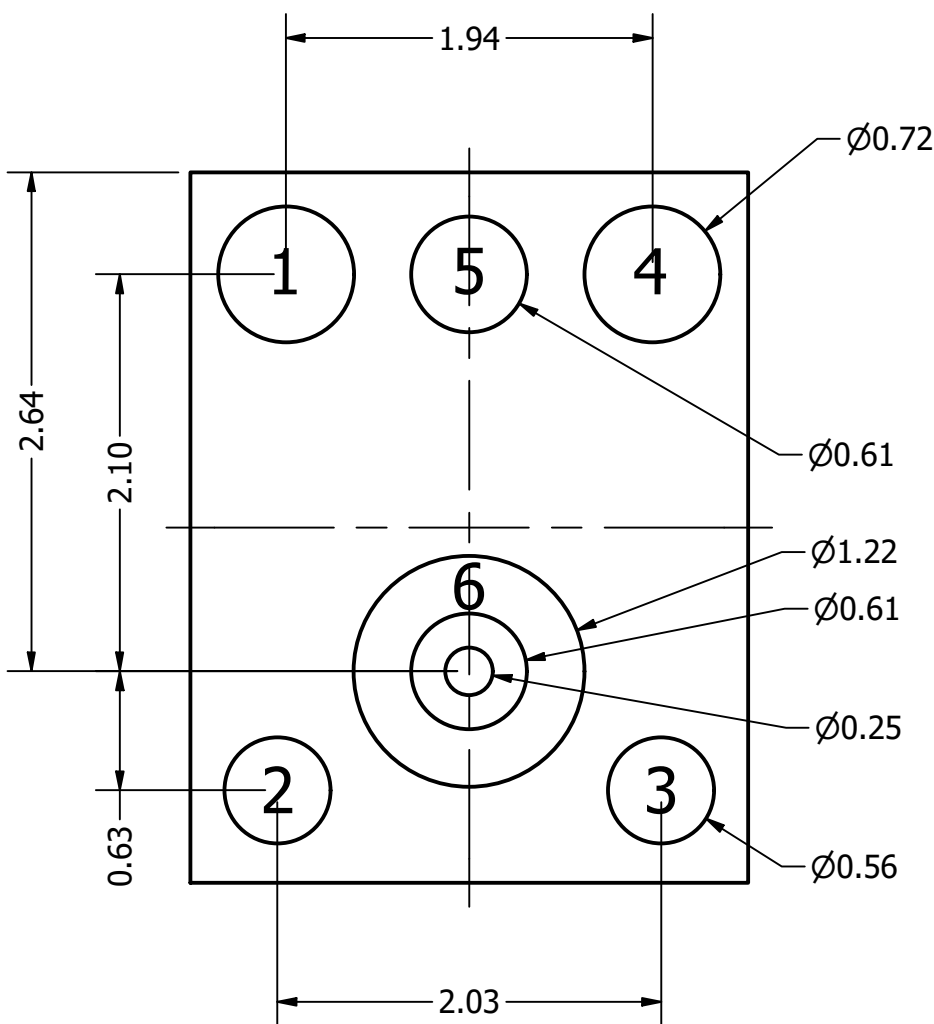

Pin 1	Pin 2	Pin 3	Pin 4	Pin 5	Pin 6
VDD	GND	GND	OUTPUT	GND	GND

Items	Specifications	Conditions
Directivity	Omnidirectional	
Sensitivity	-38 ± 1	dB
Frequency Range	100 ~ 10,000	Hz
Rated Voltage	2	V
Voltage Range	1.6 ~ 3.6	V
Output Impedance	300	Ω
Max. Rated Current	0.1	mA
Power Supply Rejection	-72	dB
Storage Temperature	-40 ~ +105	°C
Operating Temperature	-40 ~ +105	°C
Signal to Noise Ratio	63	dB
Mount Type	Surface Mount	
Connection Method	Surface Mount Pads	

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	8/16/2018	C.E.
NOTES			
1) All dimensions are in mm unless otherwise noted			
2) All tolerances are ± 0.1 mm unless otherwise noted			
3) All parts meet RoHS			
4) Subject to change or redrawn without notice			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[MM033802-7](#)