



TOP VIEW

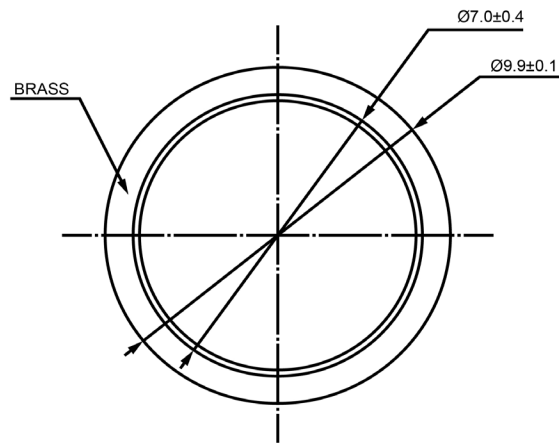

SIDE VIEW

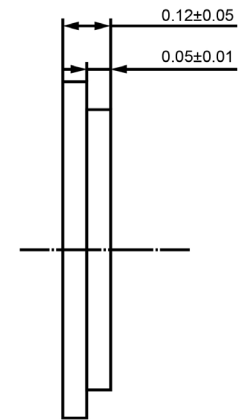

Specifications

Description	Value	Unit
Resonant Frequency	7,000	(Hz)
Resonant Impedance (Max)	1,000	(Ohm)
Max Input Voltage	15	(V)
Capacitance	10,000	(pF)
Plate Material	Brass	
Operating Temperature	-20 ~ +80	°C
Storage Temperature	-20 ~ +80	°C

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

Piezo Bender

P09070-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[P09070-1](#)