



TOP VIEW

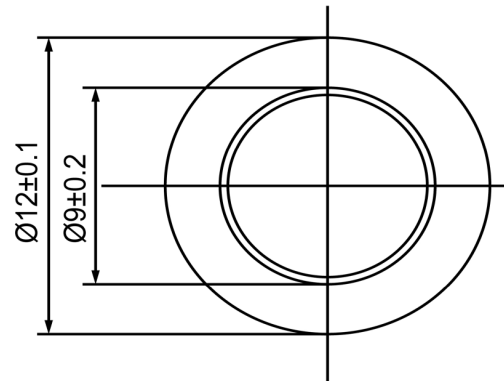

SIDE VIEW

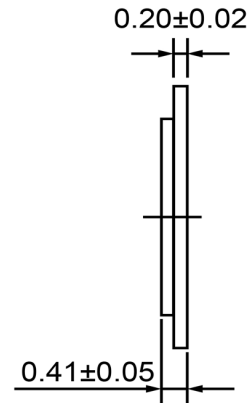

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description			Date	Approved
Resonant Frequency	16,500	(Hz)	1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering			10/21/2013	J.S
Resonant Impedance (Max)	600	(Ohm)							
Max Input Voltage	30	(V)							
Capacitance	6,000	(pF)							
Plate Material	Brass								
Operating Temperature	-20 ~ +70	°C							
Storage Temperature	-30 ~ +80	°C							

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[P12165-1](#)