





DB UNLIMITED

Part Number:	SC250708-1	
	DRAWN CJ	10/29/2015
	CHECKED P.D	11/17/2015
Description:	High Temp Dynamic Speaker	
	APPROVED J.S	11/17/2015
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

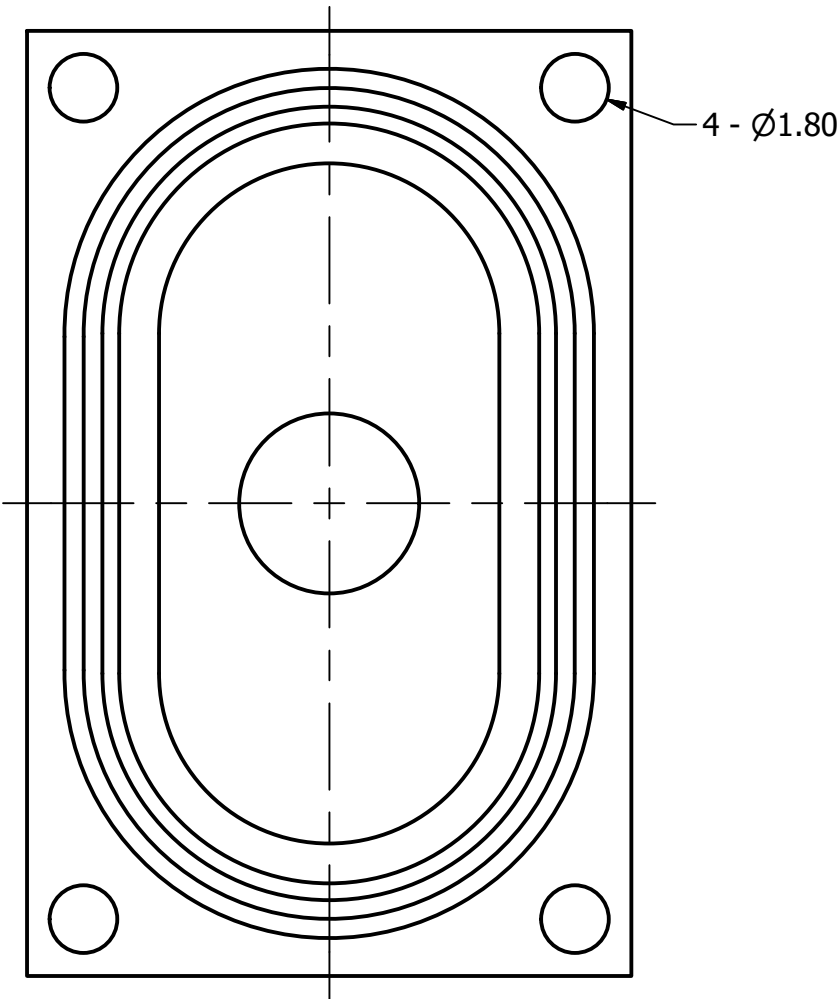

Side View

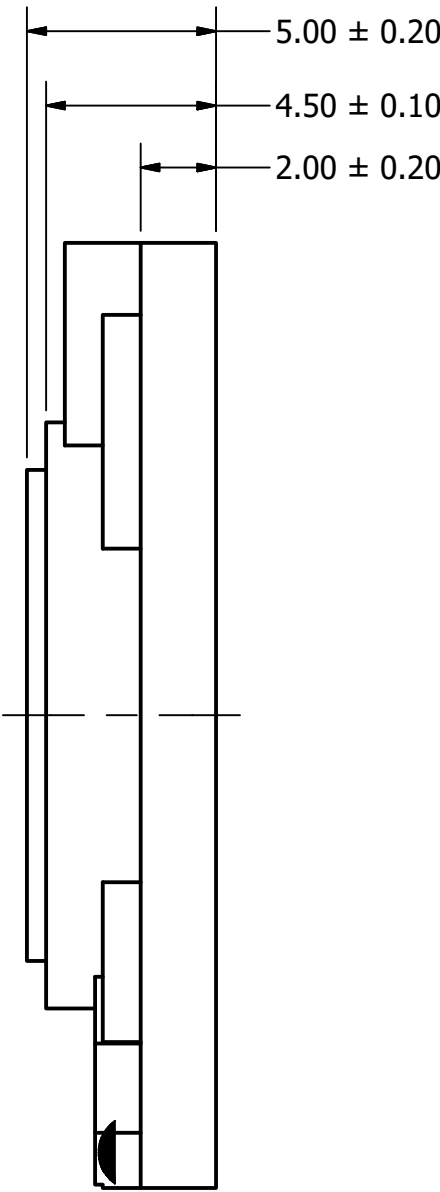

Bottom View

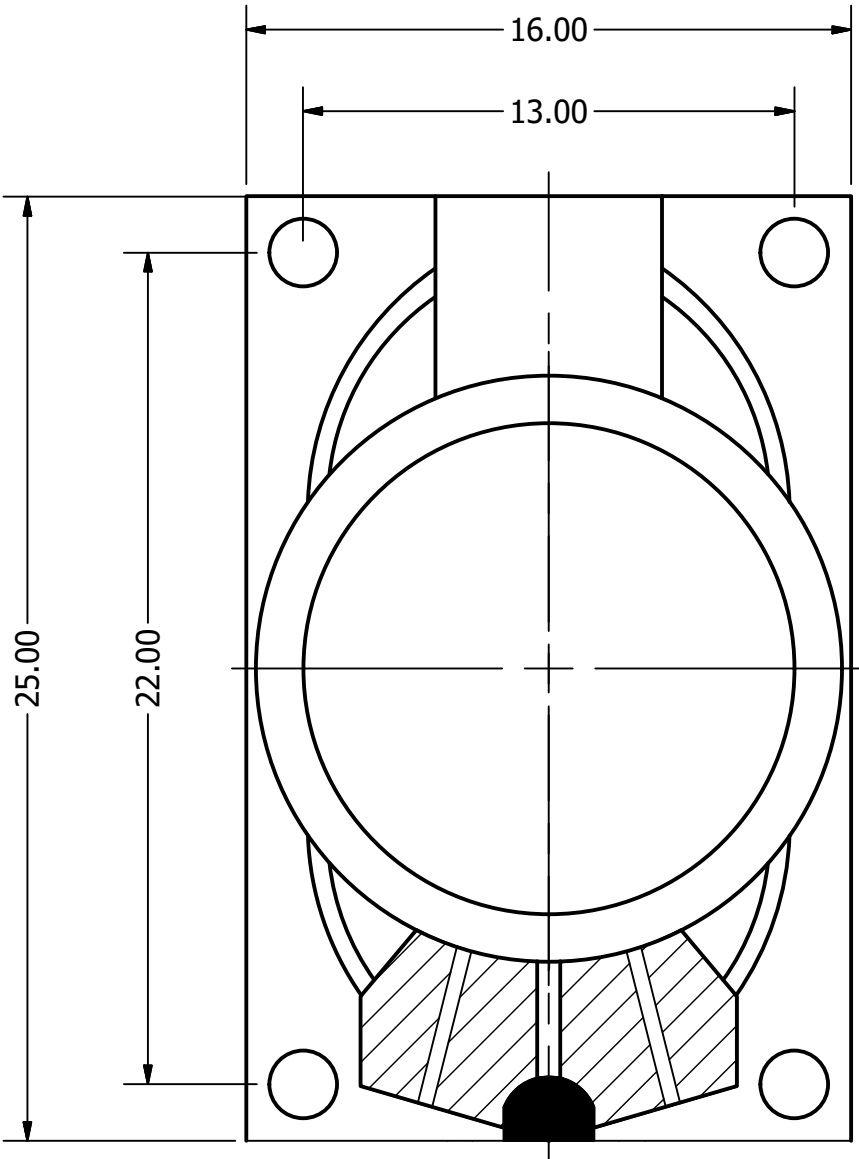

Items	Specifications	Conditions				
Sound Pressure Level	96	dB (@ 10cm)				
Resonant Frequency	750	Hz				
Frequency Range	200 ~ 20,000	Hz				
Nominal Power	1	W				
Max. Power	1.3	W				
Impedance	8	Ω				
Cone Material	Cloth					
Mount Type	Frame Mount					
Storage Temperature	-40 ~ +85	°C				
Operating Temperature	-40 ~ +85	°C				
Weight	5	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	2/8/2014	J.S.
1	New template, correct to show no wires	3/17/2017	C.E.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SC250708-1](#)