





DB UNLIMITED

Part Number:	SC400408-1	DRAWN CJ	8/9/2016
		CHECKED P.D.	8/9/2016
	Description: Dynamic Speaker	APPROVED J.S.	8/9/2016
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com			


Top View

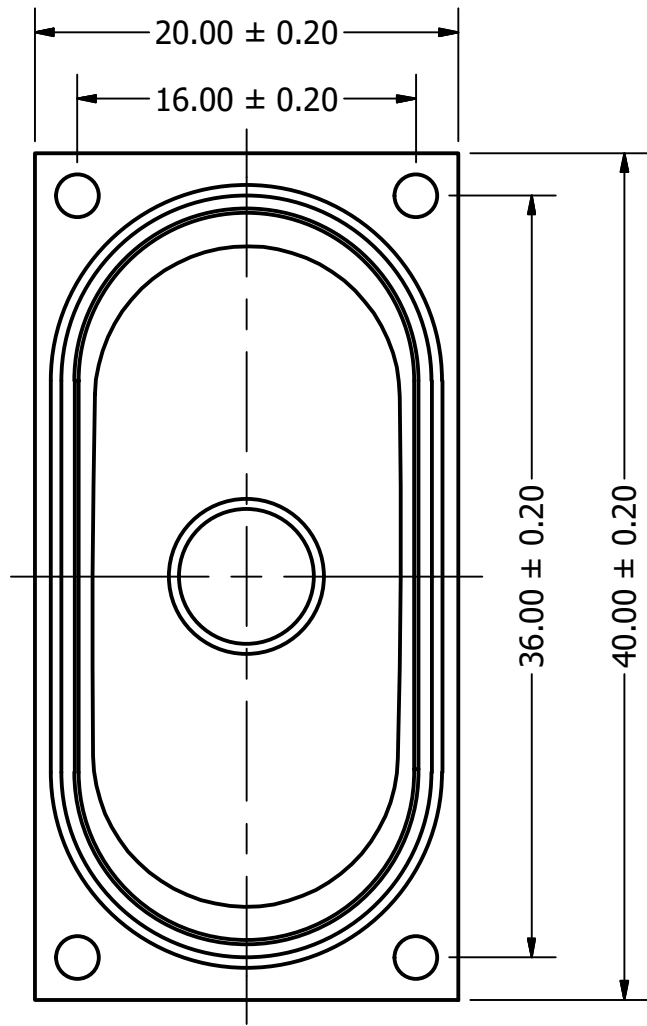

Side View

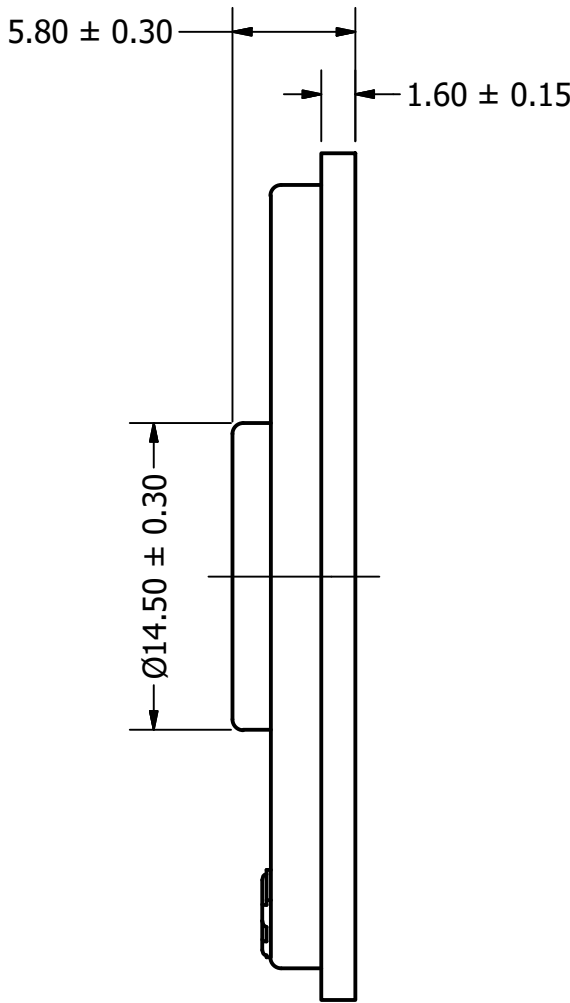

Bottom View

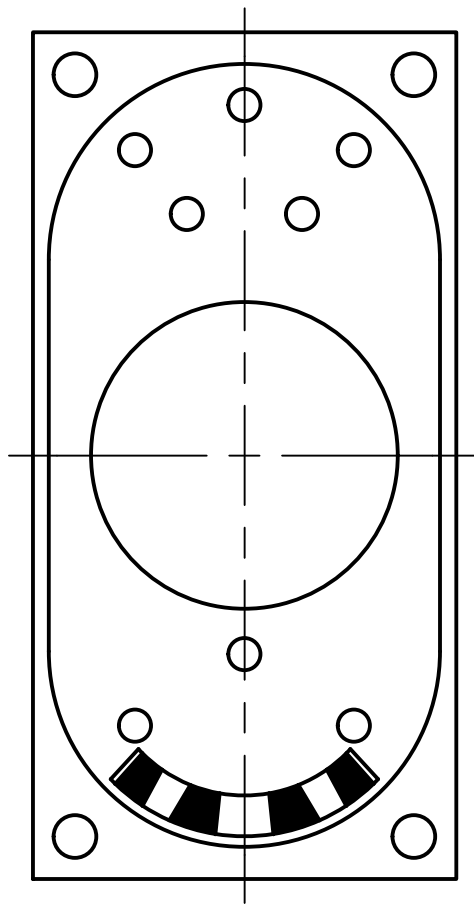

Items	Specifications	Conditions				
Sound Pressure Level	89±3	dB (@ 10cm)				
Resonant Frequency	450	Hz				
Frequency Range	450 ~ 20,000	Hz				
Nominal Power	1	W				
Max. Power	2	W				
Impedance	8	Ω				
Cone Material	Cloth					
Mount Type	Flush Mount					
Storage Temperature	-40 ~ +80	°C				
Operating Temperature	-40 ~ +70	°C				
Weight	7.6	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	2/5/2014	J.S.
1	Updated to new template	8/9/2016	J.S.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SC400408-1](#)