




TOP VIEW

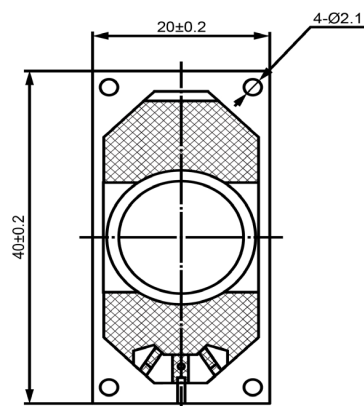

SIDE VIEW

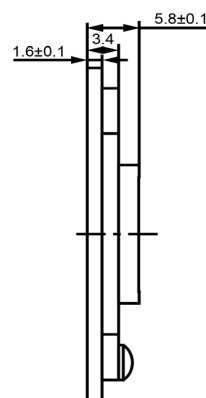

BOTTOM VIEW

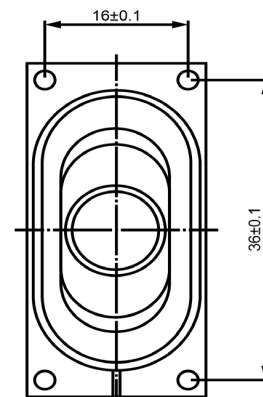

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Shape	Rectangle		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		2/5/2014	J.S.	
Resonant Frequency	650	(Hz)							
Frequency Range	200 ~ 20,000	(Hz)							
SPL @ 10cm	90	(dBA)							
Impedance	8	(Ohm)							
Cone Material	Cloth								
Nominal Power	2.0	(W)							
Max Power	2.5	(W)							
Mount Type	Frame Mount								
Operating Temperature	-40 ~ +85	°C		Drawn by	Date	Checked by	Date	Approved by	Date
Storage Temperature	-40 ~ +85	°C		G.W.	1/27/2014	C.E.	2/5/2014	J.S.	2/5/2014
Weight	7.6	(g)		High Temp Dynamic Speaker			SC400608-1		



Additional considerations can be found at [www.dbunlimitedco.com/technical-articles](http://www.dbunlimitedco.com/technical-articles).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SC400608-1](#)