





DB UNLIMITED

Part Number:	DRAWN	12/28/2015
	CJ	
	CHECKED	1/11/2016
Description:	P.D	
	APPROVED	1/11/2016
Dynamic Speaker		J.S
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>		


Top View

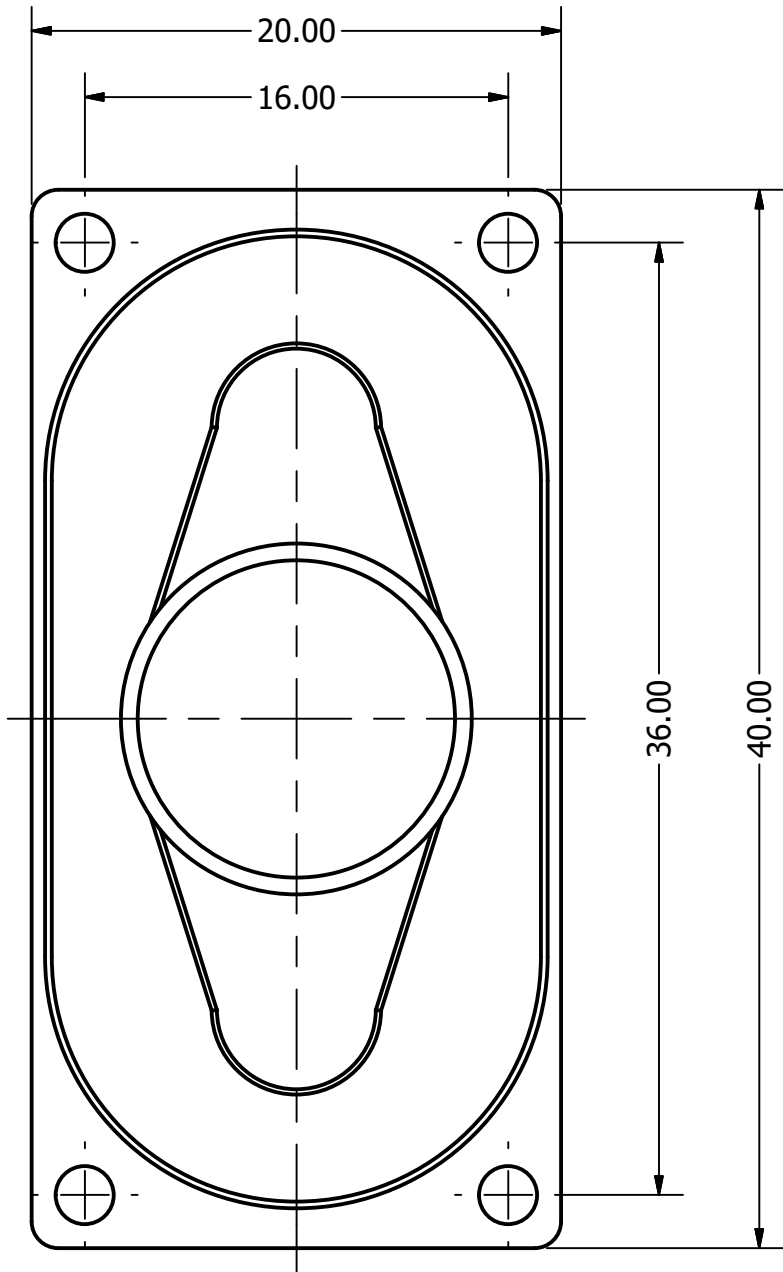

Side View

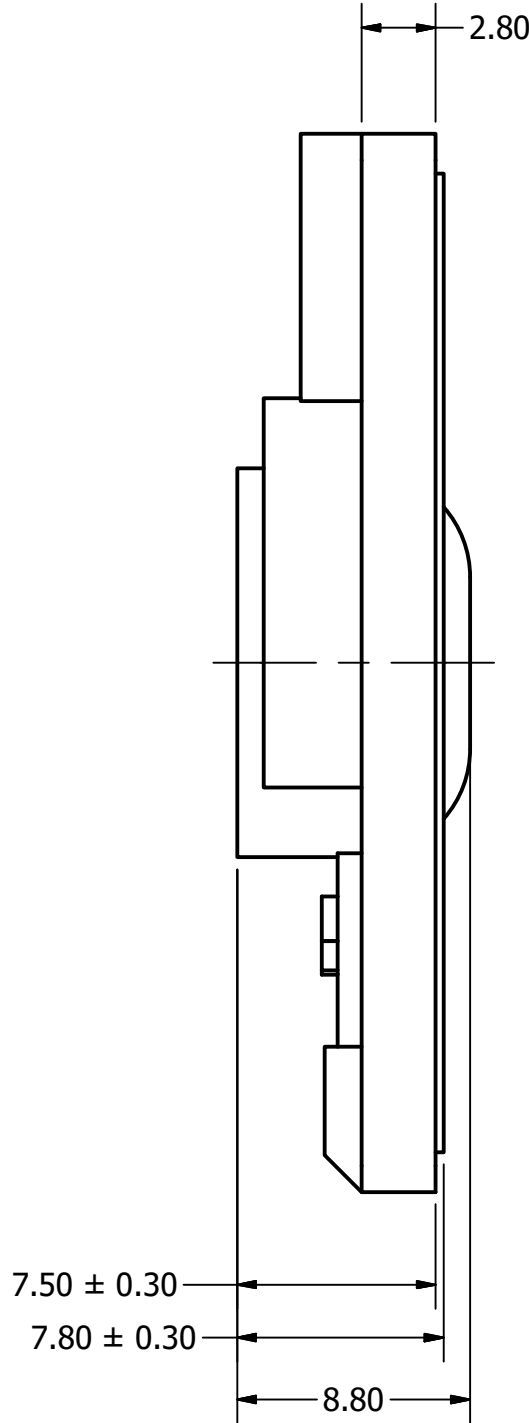

Bottom View

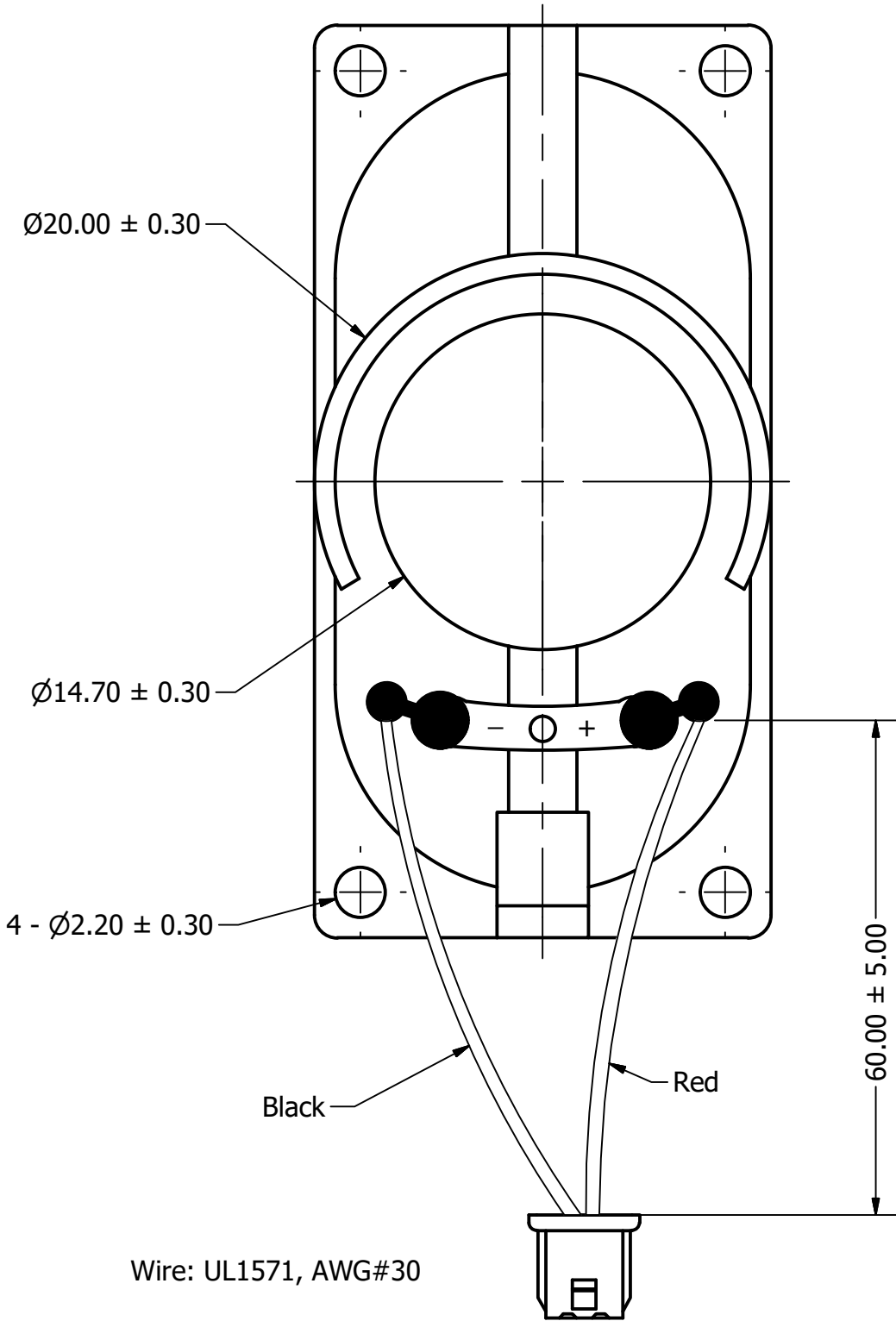

Wire: UL1571, AWG#30

Items	Specifications	Conditions				
Sound Pressure Level	90	dB (@ 10cm)				
Resonant Frequency	900	Hz				
Frequency Range	900 ~ 20,000	Hz				
Nominal Power	1	W				
Max. Power	1.5	W				
Impedance	8	Ω				
Cone Material	Cloth					
Mount Type	Frame Mount					
Storage Temperature	-25 ~ +85	°C				
Operating Temperature	-25 ~ +85	°C				
Weight	6.5	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	1/27/2014	J.S.
1	Updated to new template	1/11/2016	J.S.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SC400908-2](#)