





Part Number: SC600204-1	DRAWN CJ	4/5/2016
	CHECKED P.D.	4/6/2016
	APPROVED J.S.	4/6/2016
Description: Dynamic Speaker		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		

Top View

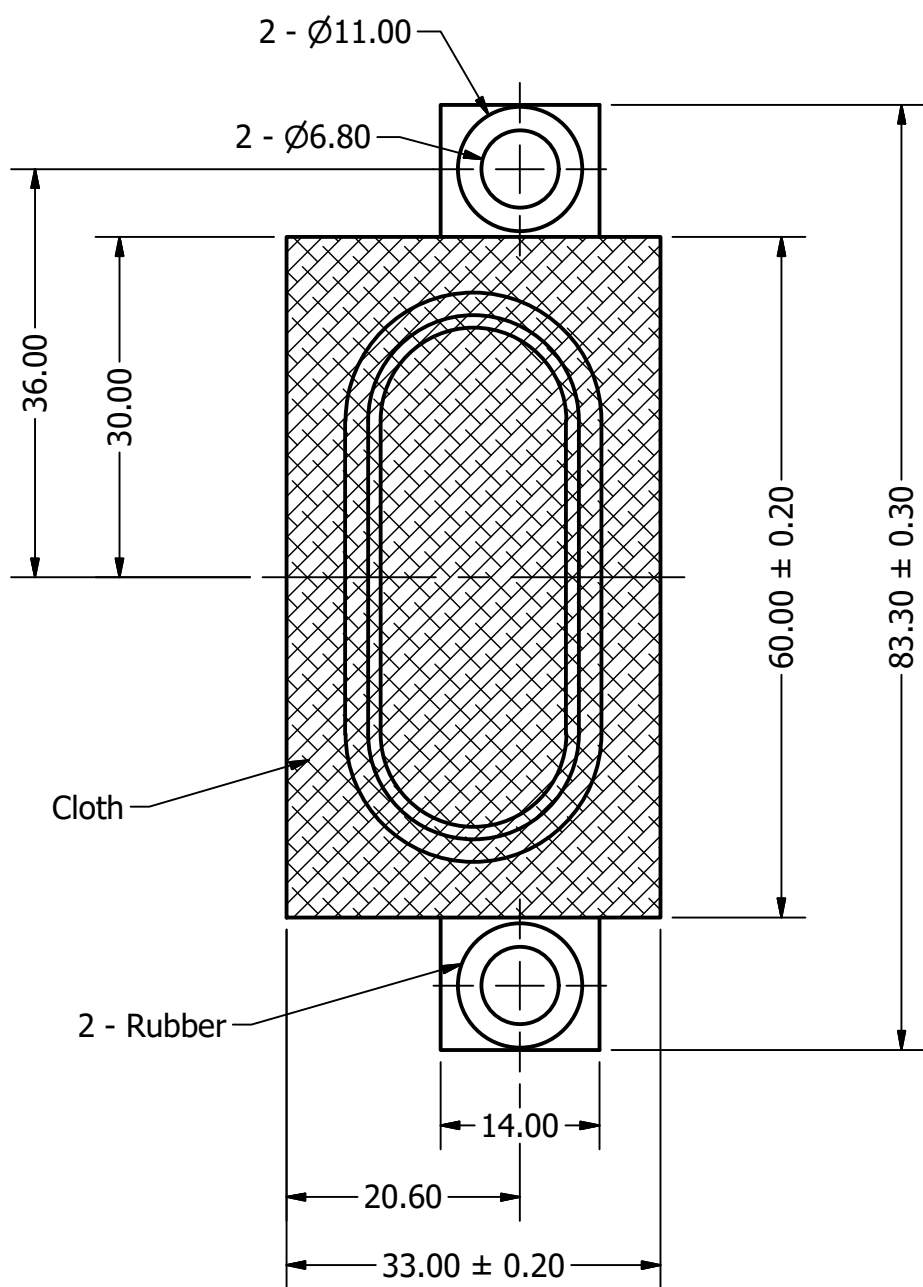

Side View

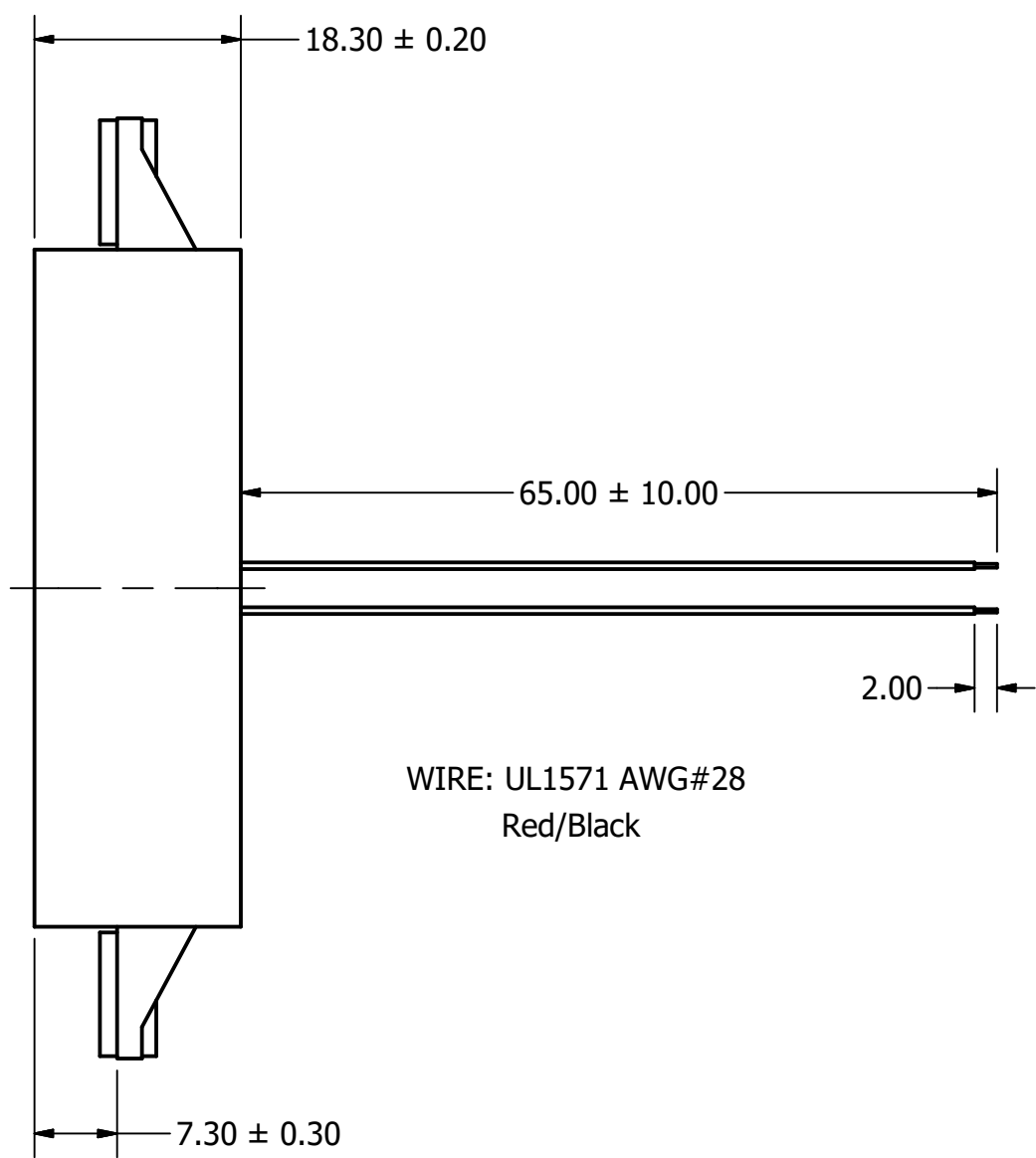

Items	Specifications	Conditions				
Sound Pressure Level	100	dB (@ 10cm)				
Resonant Frequency	250	Hz				
Frequency Range	200 ~ 20,000	Hz				
Nominal Power	2	W				
Max. Power	4	W				
Impedance	4	Ω				
Cone Material	Cloth					
Mount Type	Flange Mount					
Storage Temperature	-30 ~ +70	°C				
Operating Temperature	-20 ~ +60	°C				
Weight	7.6	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
1	Released from Engineering	12/11/2013	J.S.
	Updated to new template	4/6/2016	J.S.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SC600204-1](#)