



TOP VIEW

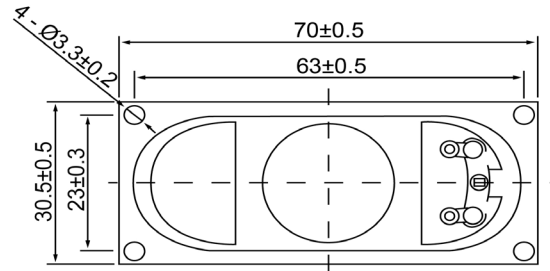

SIDE VIEW

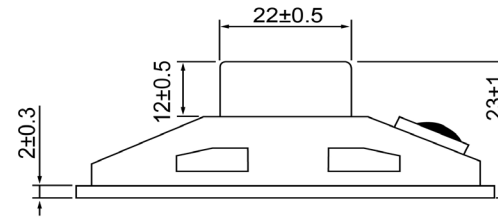

Specifications

Description	Value	Unit
Shape	Rectangle	
Resonant Frequency	300	(Hz)
Frequency Range	200 ~ 20,000	(Hz)
SPL @ 10cm	100	(dBA)
Impedance	8	(Ohm)
Cone Material	Cloth	
Nominal Power	2	(W)
Max Power	5	(W)
Mount Type	Frame Mount	
Operating Temperature	-40 ~ +80	°C
Storage Temperature	-40 ~ +80	°C
Weight	7.6	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

High Temp Dynamic Speaker

Revision History

Version	Description			Date	Approved
1	Released from Engineering			2/5/2014	J.S.

SC700308-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SC700308-1](#)