




SIDE VIEW

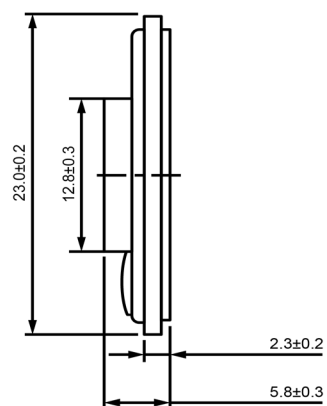

BOTTOM VIEW

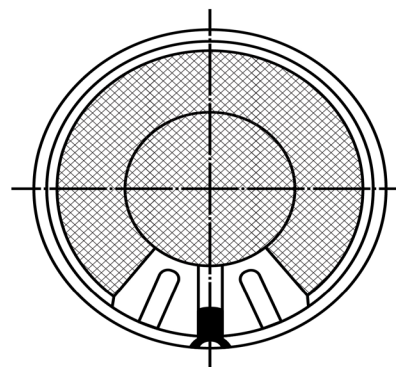

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	340	(Hz)								
Frequency Range	340 ~ 20,000	(Hz)								
SPL @ 10cm	78	(dBA)								
Impedance	32	(Ohm)								
Cone Material	Mylar									
Nominal Power	0.08	(W)								
Max Power	0.15	(W)								
Mount Type	Flush									
Operating Temperature	-25 ~ +60	°C								
Storage Temperature	-25 ~ +60	°C		Drawn by		Date	Checked by	Date	Approved by	Date
Weight	4.7	(g)		A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			DB UNLIMITED	Dynamic Speaker			SM230332-1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM230332-1](#)