



Part Number:	SM310204-1	
	DRAWN CJ	4/16/2019
	CHECKED C.H.	5/16/2019
Description:	Dynamic Speaker	
	APPROVED C.E.	5/16/2019
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>		


Top View

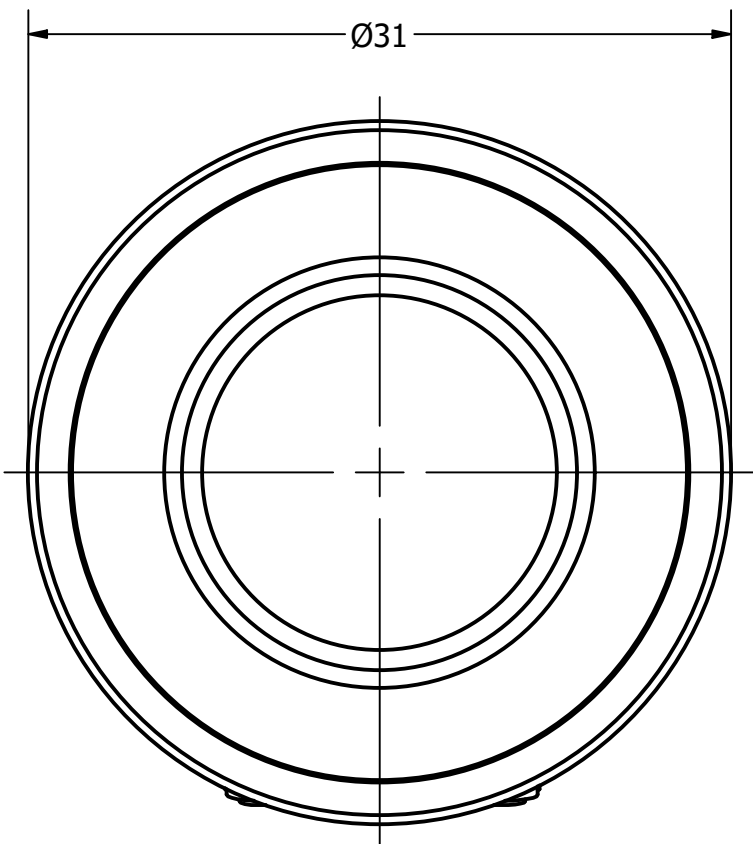

Side View

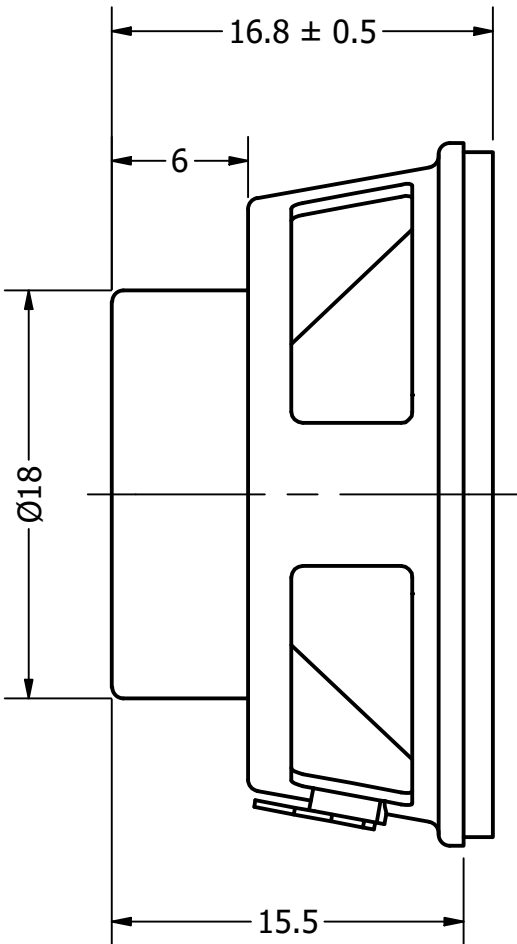

Bottom View

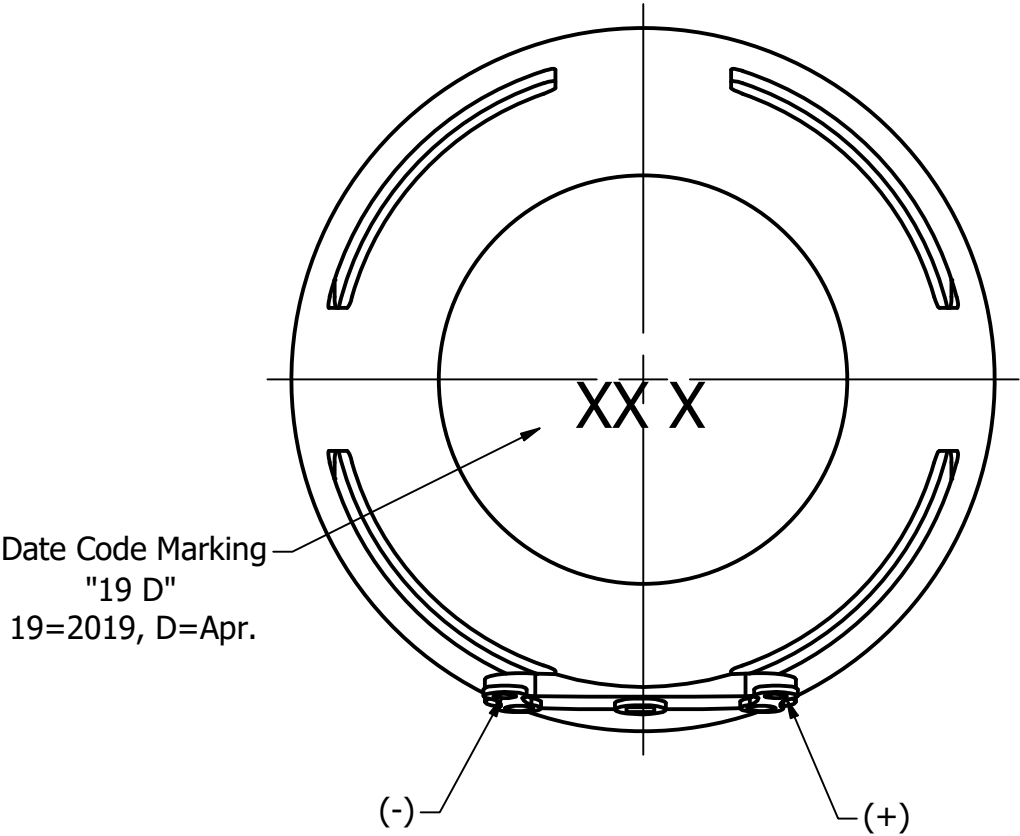

Items	Specifications	Conditions				
Sound Pressure Level	97	dB (@ 10cm), Avg.				
Resonant Frequency	240	Hz				
Frequency Range	240 ~ 10,000	Hz				
Nominal Power	2	W	REV	DESCRIPTION	DATE	APPROVED
Max. Power	2.5	W		Released from Engineering	5/16/2019	C.E.
Impedance	4	Ω				
Cone Material	Mylar					
Mount Type	Flush Mount					
Storage Temperature	-20 ~ +55	°C				
Operating Temperature	-20 ~ +55	°C				
			REVISION HISTORY			
			NOTES			
			1) All dimensions are in mm unless otherwise noted			
			2) All tolerances are ± 0.3 mm unless otherwise noted			
			3) All parts meet RoHS			
			4) Subject to change or redrawn without notice			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM310204-1](#)