




TOP VIEW

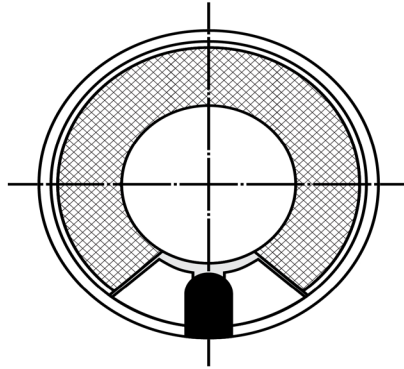

SIDE VIEW

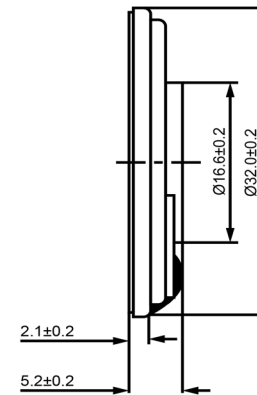

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S	
Resonant Frequency	668	(Hz)							
Frequency Range	668 ~ 9,000	(Hz)							
SPL @ 10cm	92	(dBA)							
Impedance	32	(Ohm)							
Cone Material	Mylar								
Nominal Power	0.5	(W)							
Max Power	1	(W)							
Mount Type	Flush								
Operating Temperature	-40 ~ +85	°C							
Storage Temperature	-40 ~ +85	°C		Drawn by	Date	Checked by	Date	Approved by	Date
Weight	7.95	(g)		A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
DB UNLIMITED			High Temp Dynamic Speaker			SM320632-1			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM320632-1](#)