




SIDE VIEW

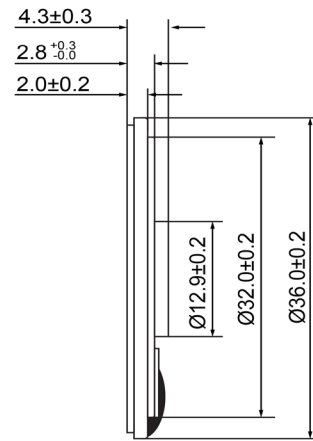

BOTTOM VIEW

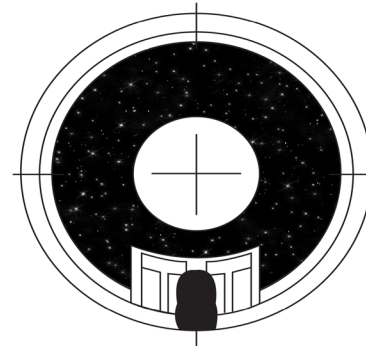

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S	
Resonant Frequency	420	(Hz)							
Frequency Range	420 ~ 5,600	(Hz)							
SPL @ 10cm	93	(dBA)							
Impedance	16	(Ohm)							
Cone Material	Mylar								
Nominal Power	0.2	(W)							
Max Power	0.4	(W)							
Mount Type	Flush								
Operating Temperature	-40 ~ +66	°C							
Storage Temperature	-40 ~ +66	°C		Drawn by	Date	Checked by	Date	Approved by	Date
Weight	8.7	(g)		A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			DB UNLIMITED	Dynamic Speaker			SM360416-2		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM360416-2](#)