





DB UNLIMITED

Part Number:	SM500416-1	
	DRAWN	CJ
	CHECKED	C.H.
Description:	Dynamic Speaker	
	APPROVED	C.E.
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>		


Top View

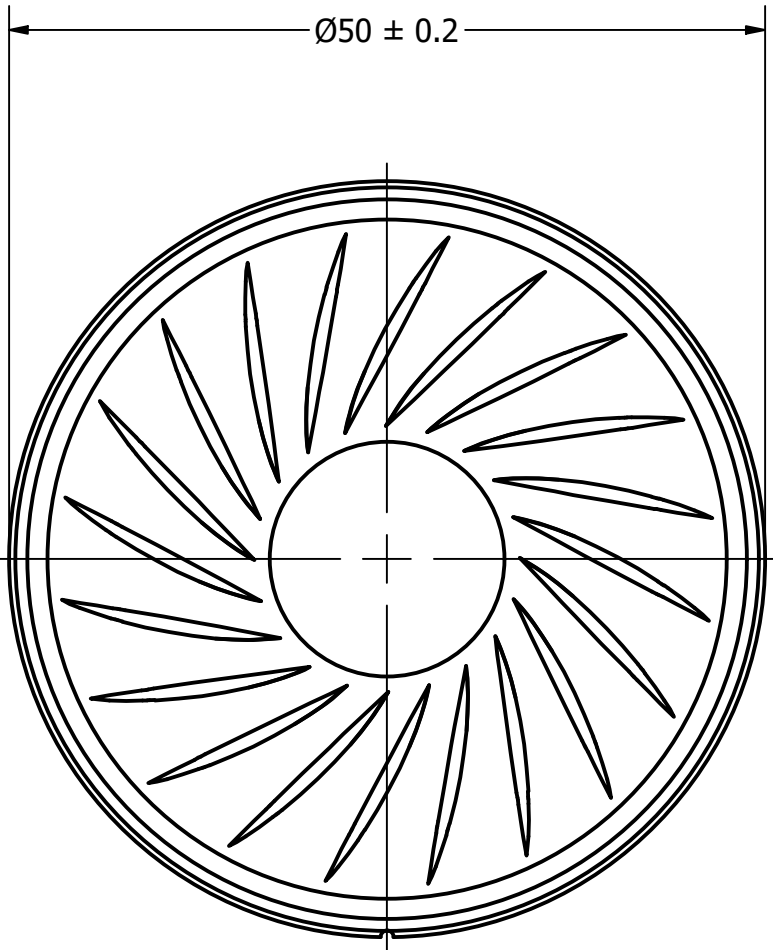

Side View

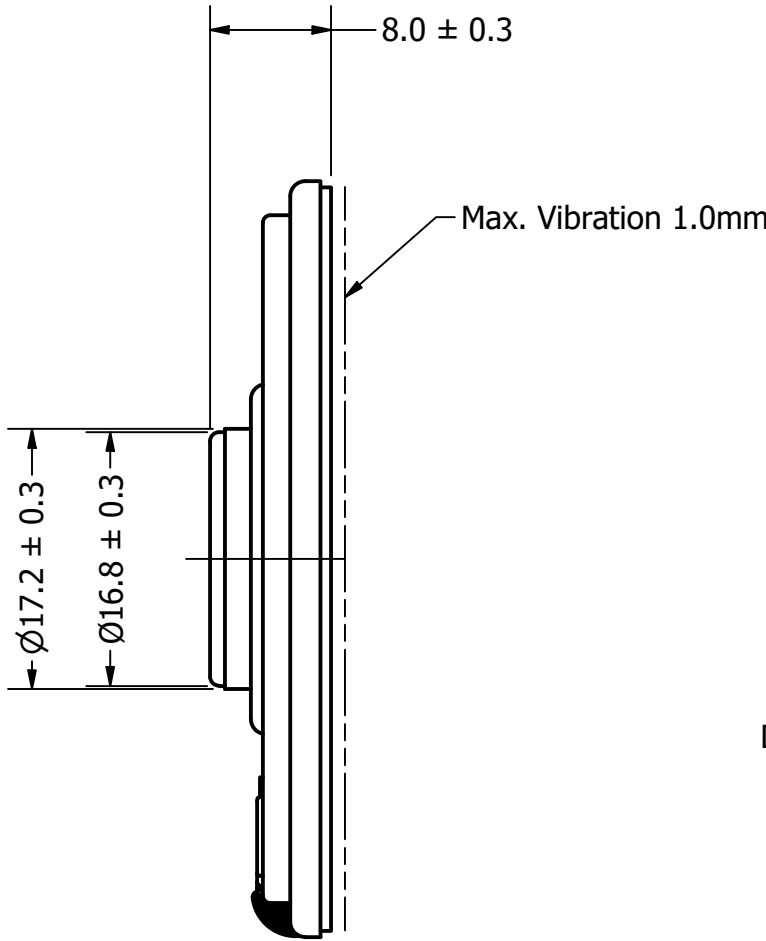

Bottom View

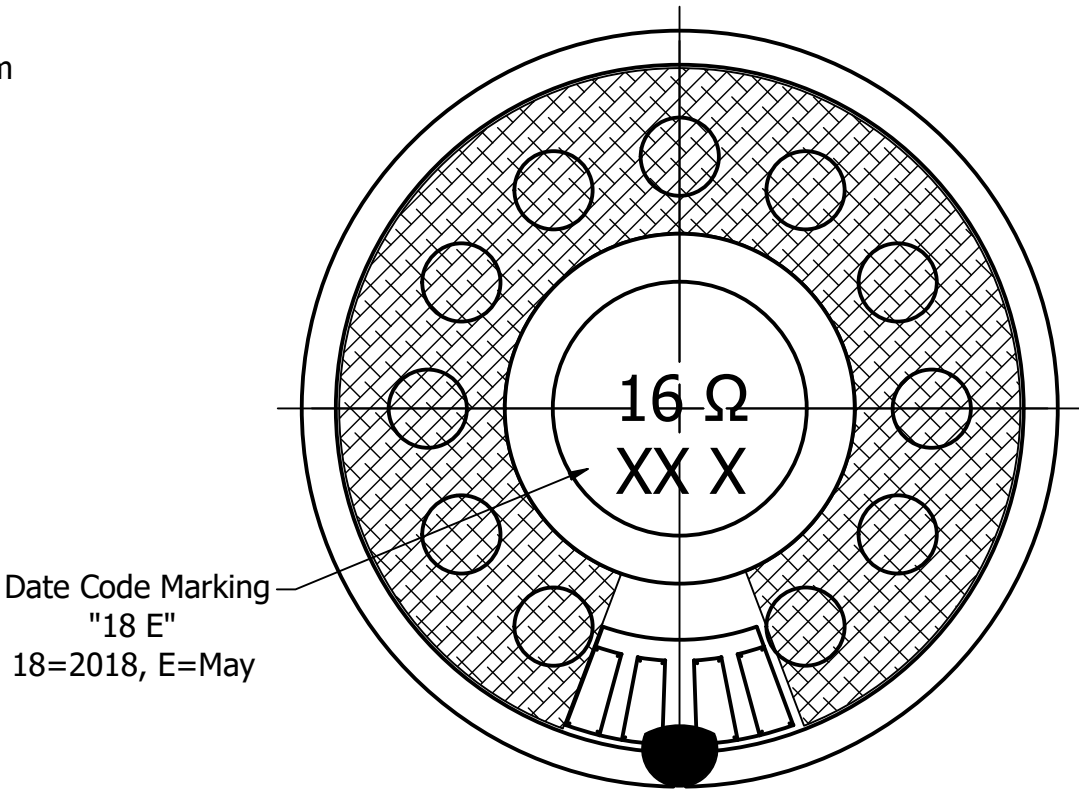

Items	Specifications	Conditions				
Sound Pressure Level	97	dB (@ 10cm), Avg.	REVISION HISTORY			
Resonant Frequency	400	Hz	REV	DESCRIPTION	DATE	APPROVED
Frequency Range	400 ~ 5,000	Hz		Released from Engineering	5/30/2018	C.E.
Nominal Power	0.25	W	1	Update back magnet detail	2/3/2018	C.E.
Max. Power	0.5	W	NOTES			
Impedance	16	Ω	1) All dimensions are in mm unless otherwise noted			
Cone Material	Mylar		2) All tolerances are ± 0.5 mm unless otherwise noted			
Mount Type	Flush Mount		3) All parts meet RoHS			
Storage Temperature	-30 ~ +70	°C	4) Subject to change or redrawn without notice			
Operating Temperature	-20 ~ +60	°C				

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM500416-1](#)