




SIDE VIEW

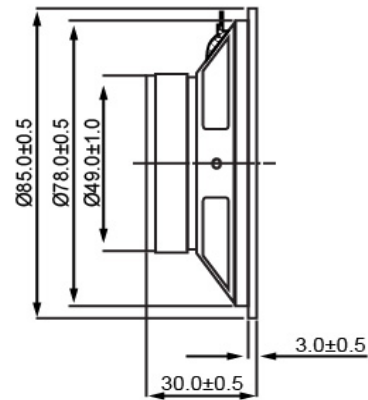

BOTTOM VIEW

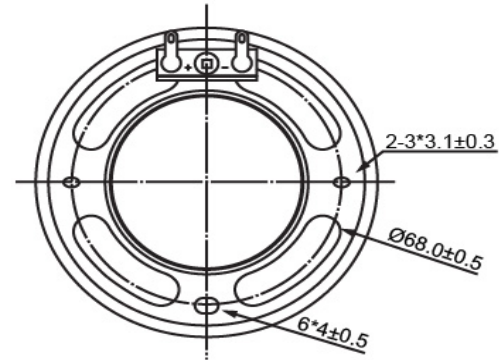

Specifications			Notes	Revision History							
Description	Value	Unit		Version	Description			Date	Approved		
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering			10/21/2013	J.S		
Resonant Frequency	350	(Hz)									
Frequency Range	350 ~ 6,000	(Hz)									
SPL @ 10cm	104	(dBA)									
Impedance	16	(Ohm)									
Cone Material	Mylar										
Nominal Power	10	(W)									
Max Power	15	(W)									
Mount Type	Flush										
Operating Temperature	-20 ~ +55	°C									
Storage Temperature	-20 ~ +55	°C									
Weight	197	(g)									
 DB UNLIMITED				Drawn by			Date	Checked by	Date	Approved by	Date
				A.B.			10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			Dynamic Speaker			SM850316-1					

Additional considerations can be found at www.dbunlimitedco.com/technical-services.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM850316-1](#)