



Part Number:	SP280304-2	
	DRAWN CJ	4/16/2019
Description:	CHECKED C.H.	5/16/2019
	APPROVED C.E.	5/16/2019
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

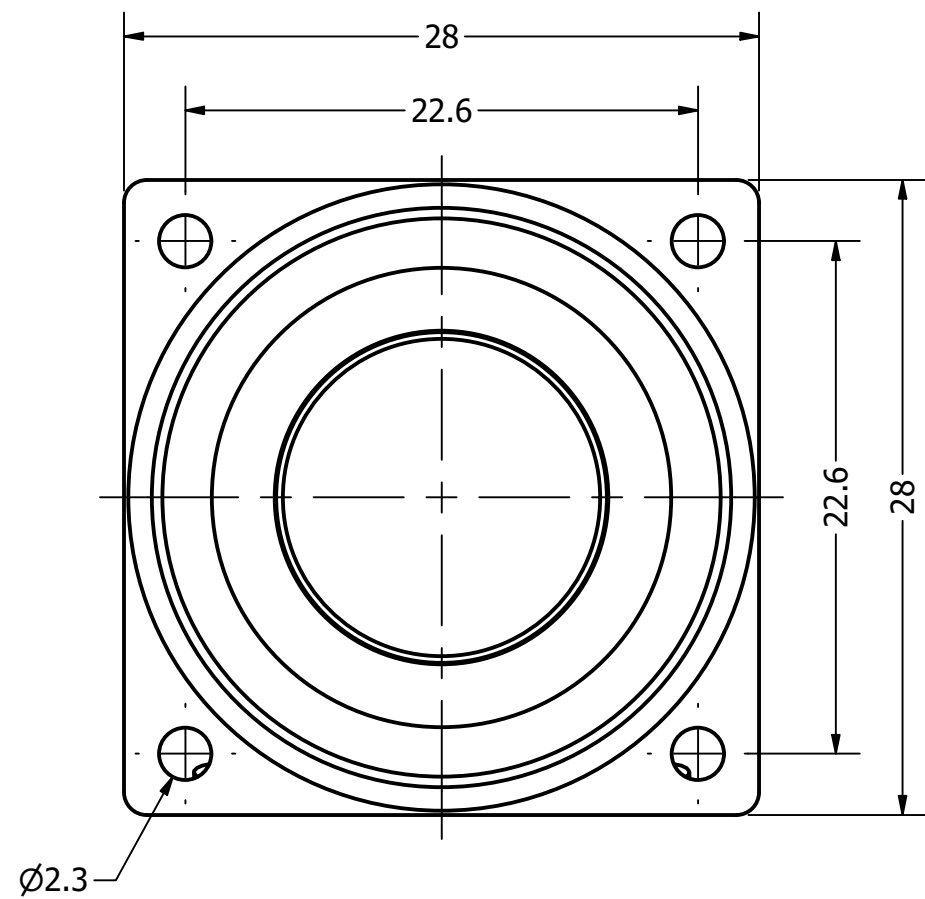

Side View

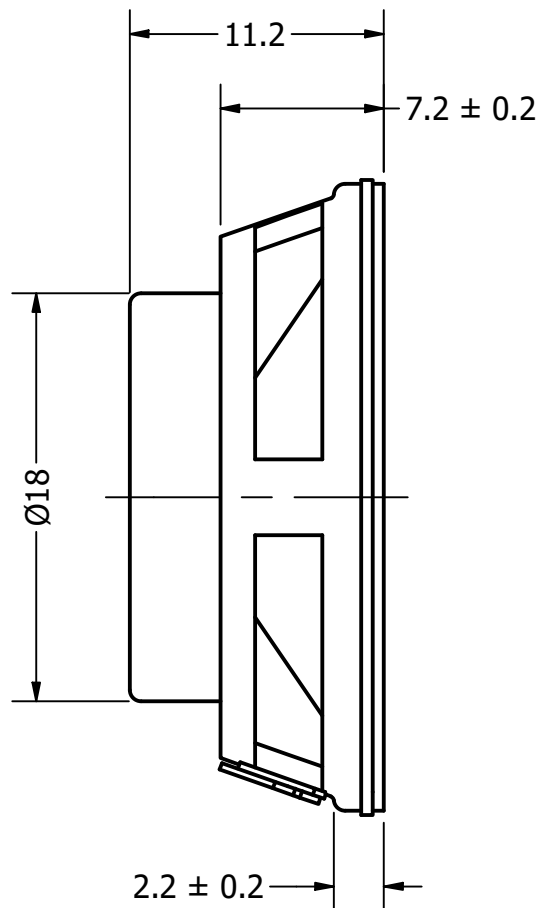

Bottom View

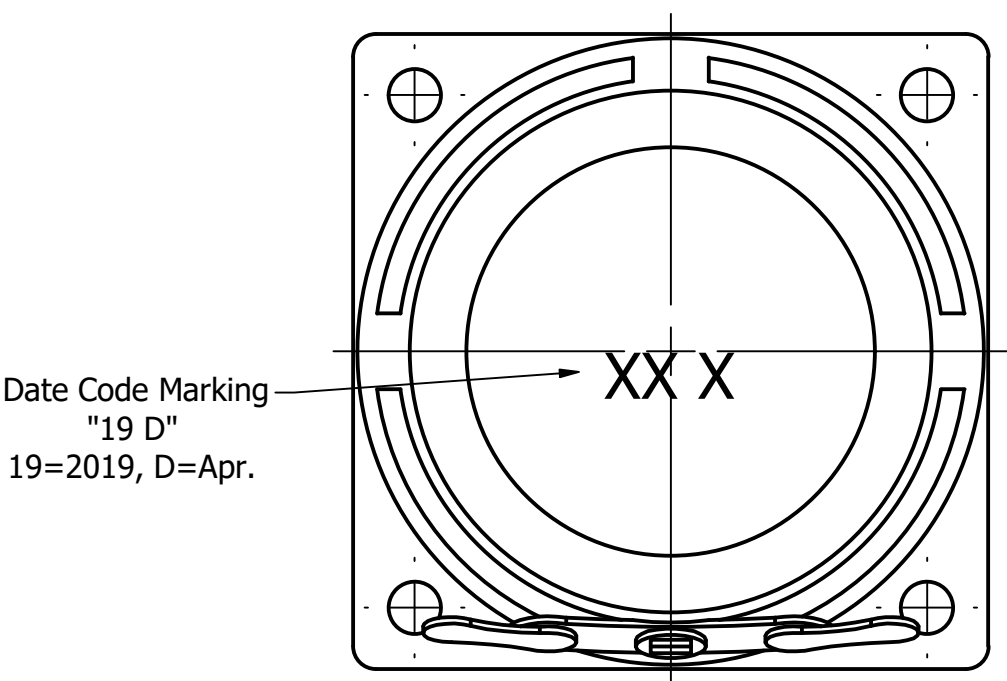

Items	Specifications	Conditions				
Sound Pressure Level	94	dB (@ 10cm), Avg.				
Resonant Frequency	380	Hz	REVISION HISTORY			
Frequency Range	380 ~ 20,000	Hz	REV	DESCRIPTION	DATE	APPROVED
Nominal Power	2	W		Released from Engineering	5/16/2019	C.E.
Max. Power	3	W	1	Updated top and side view, solder eyelets added	6/18/2019	J.S.
Impedance	4	Ω	NOTES			
Cone Material	PU + Paper		1) All dimensions are in mm unless otherwise noted			
Mount Type	Frame Mount		2) All tolerances are ± 0.5 mm unless otherwise noted			
Storage Temperature	-30 ~ +70	°C	3) All parts meet RoHS			
Operating Temperature	-20 ~ +60	°C	4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP280304-2](#)