



Part Number:	SP500104-1	DRAWN	
		CJ	9/24/2015
		CHECKED	
Description:	Dynamic Speaker	P.D	9/24/2015
		APPROVED	
		J.S	9/24/2015
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com			


Top View

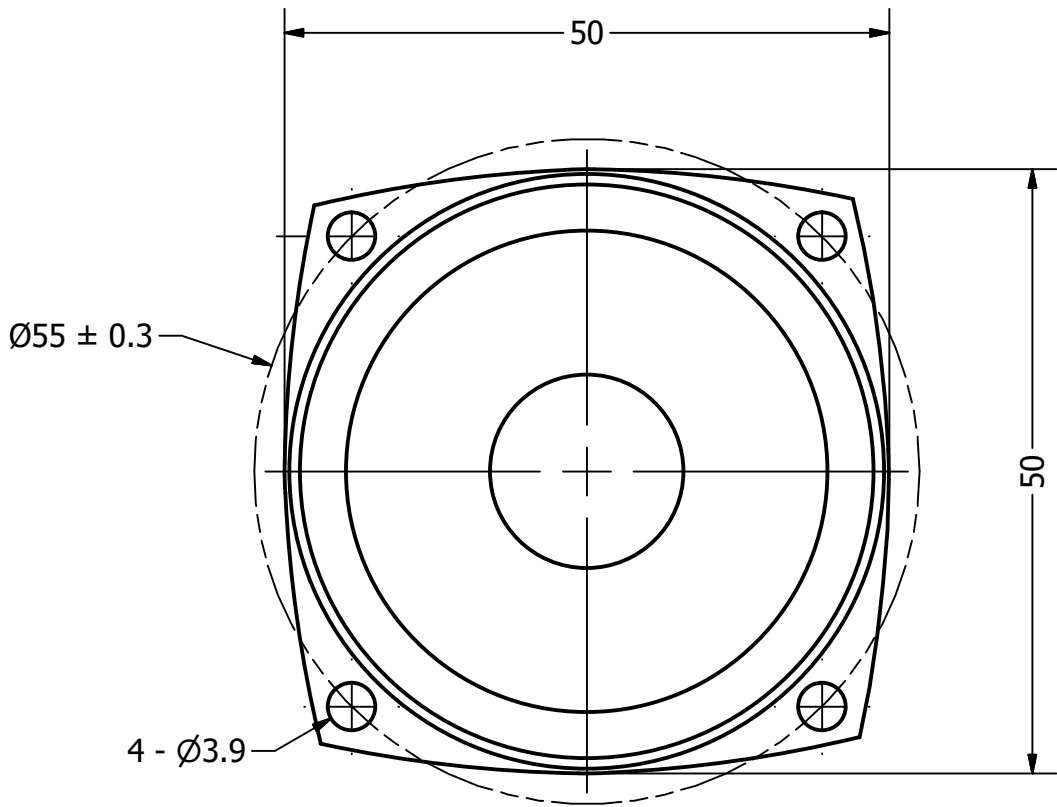

Side View

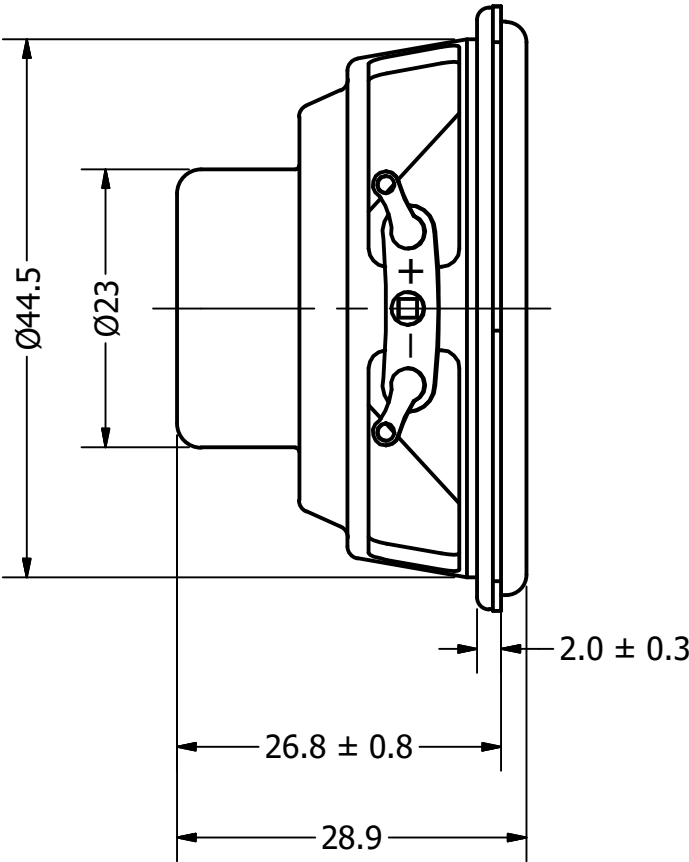

Bottom View

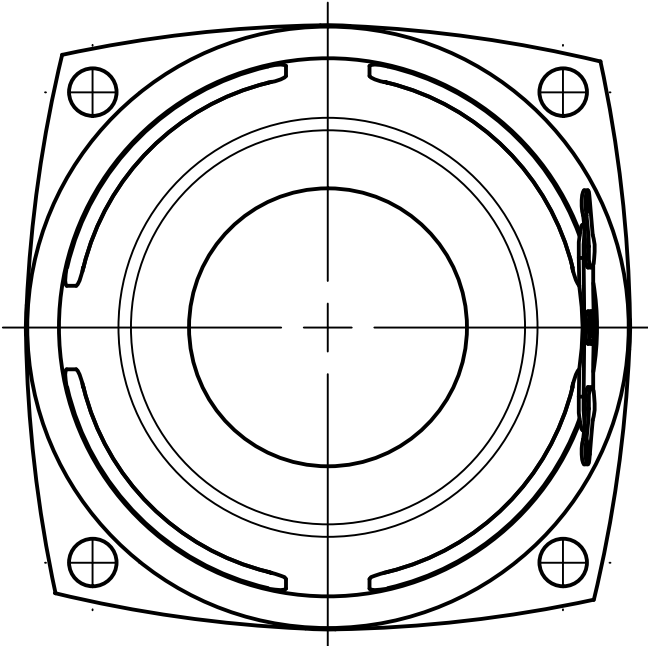

Items		Specifications	Conditions			
Sound Pressure Level		101	dB (@ 10cm)			
Resonant Frequency		135	Hz	REV	DESCRIPTION	DATE
Frequency Range		135 ~ 20,000	Hz		Released from Engineering	10/21/2013
Nominal Power		5	W	1	Updated to new template	9/24/2015
Max. Power		10	W	2	Added bottom view	6/19/2017
Impedance		4	Ω			
Cone Material		Paper				
Mount Type		Frame				
Storage Temperature		-25 ~ +55	°C			
Operating Temperature		-25 ~ +55	°C			
Weight		30	g			

- NOTES
- 1) All dimensions are in mm unless otherwise noted
 - 2) All tolerances are ± 0.5 mm unless otherwise noted
 - 3) All parts meet RoHS
 - 4) Subject to change or redrawn without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP500104-1](#)