



SIDE VIEW

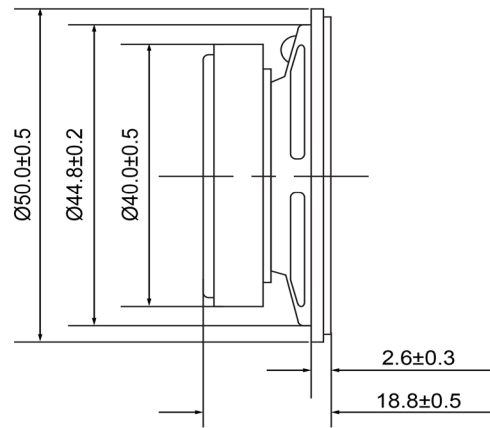

BOTTOM VIEW

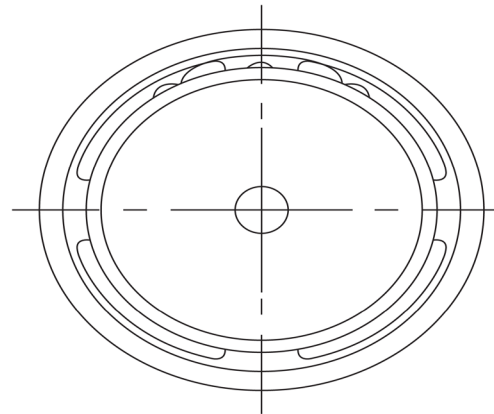

## Specifications

Description	Value	Unit
Shape	Round	
Resonant Frequency	400	(Hz)
Frequency Range	400 ~ 4,000	(Hz)
SPL @ 10cm	86	(dBA)
Impedance	50	(Ohm)
Cone Material	Paper	
Nominal Power	0.25	(W)
Max Power	0.5	(W)
Mount Type	Flush	
Operating Temperature	-25 ~ +55	°C
Storage Temperature	-25 ~ +55	°C
Weight	55	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted  
 2) All parts meet RoHS



DB UNLIMITED

Dynamic Speaker

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

SP500450-1

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP500450-1](#)