



Part Number:	1	
	DRAWN	11/9/2018
	CJ	
Description:	CHECKED	11/9/2018
	C.H.	
	APPROVED	11/9/2018
	C.E.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

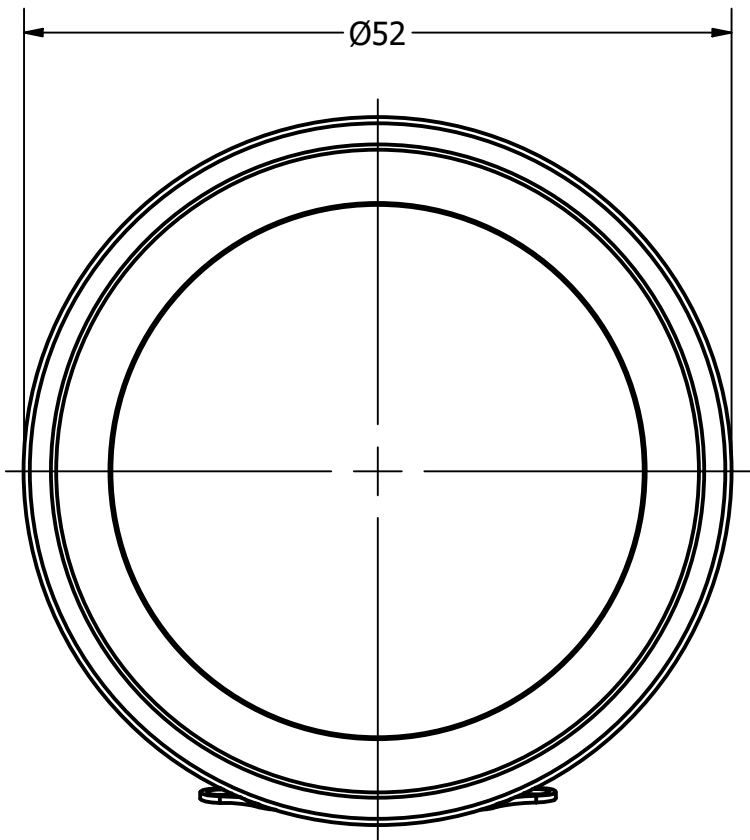

Side View

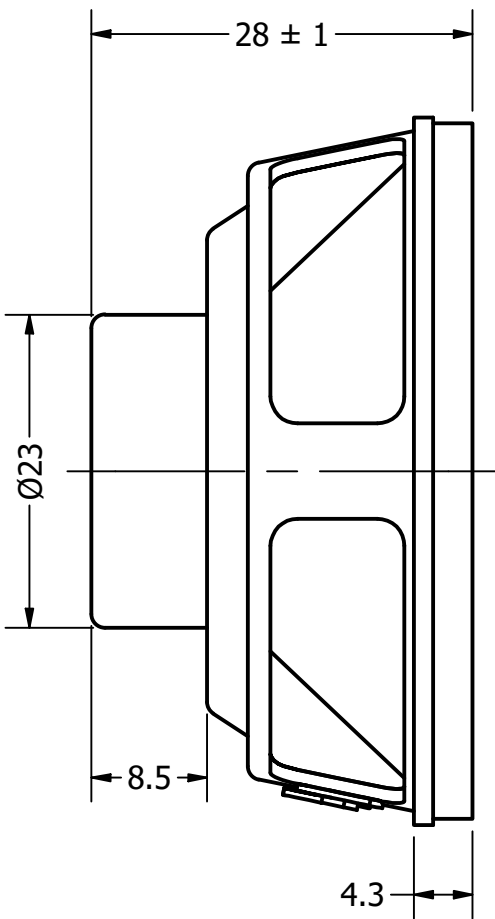

Bottom View

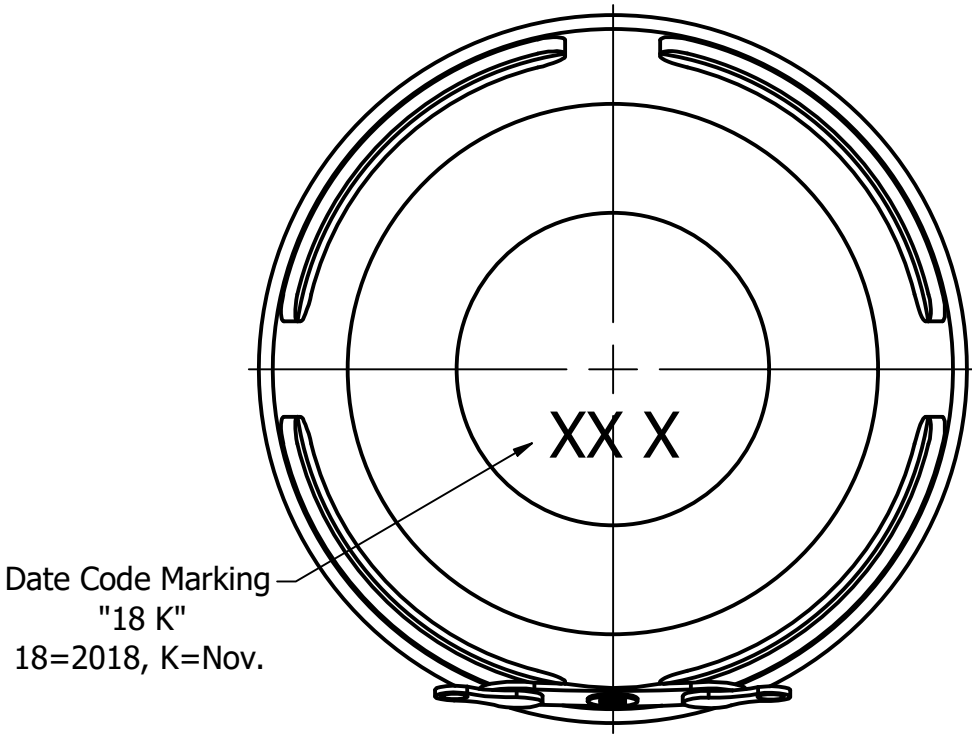

Items	Specifications	Conditions				
Sound Pressure Level	99	dB (@ 10cm), Avg.				
Resonant Frequency	150	Hz				
Frequency Range	150 ~ 20,000	Hz				
Nominal Power	5	W				
Max. Power	6	W				
Impedance	4	Ω				
Cone Material	Paper					
Mount Type	Flush Mount					
IP Rating	IP65					
Storage Temperature	-40 ~ +85	°C				
Operating Temperature	-30 ~ +75	°C				
Weight	34	g				
			REVISION HISTORY			
			REV	DESCRIPTION	DATE	APPROVED
				Released from Engineering	11/9/2018	C.E.
			NOTES			
			1) All dimensions are in mm unless otherwise noted			
			2) All tolerances are ± 0.5 mm unless otherwise noted			
			3) All parts meet RoHS			
			4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP520104-1](#)