



TOP VIEW

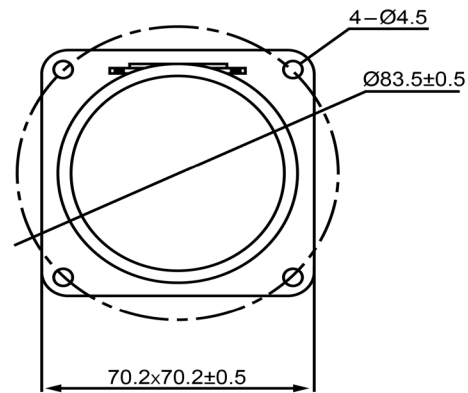

SIDE VIEW

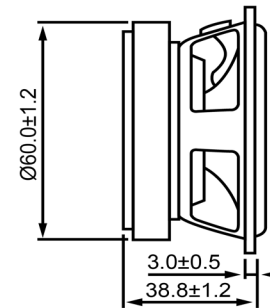

Specifications

Description	Value	Unit
Shape	Rectangle	
Resonant Frequency	95	(Hz)
Frequency Range	95 ~ 3,500	(Hz)
SPL @ 10cm	96	(dBA)
Impedance	8	(Ohm)
Cone Material	Paper	
Nominal Power	10	(W)
Max Power	15	(W)
Mount Type	Frame	
Operating Temperature	-25 ~ +55	°C
Storage Temperature	-25 ~ +55	°C
Weight	288	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Dynamic Speaker

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

SP700108-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP700108-1](#)