




SIDE VIEW

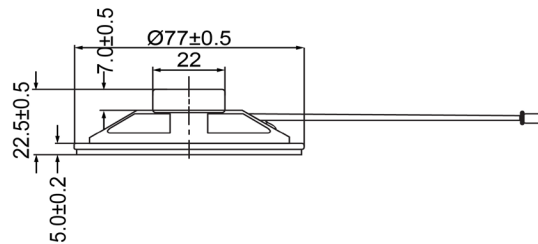

BOTTOM VIEW

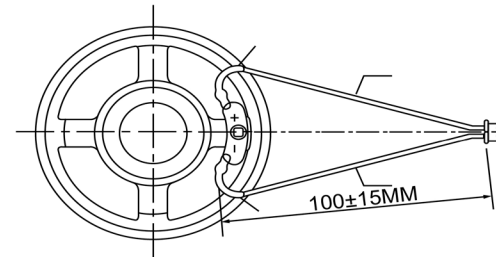

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	280	(Hz)								
Frequency Range	280 ~ 15,000	(Hz)								
SPL @ 10cm	107	(dBA)								
Impedance	35	(Ohm)								
Cone Material	Paper									
Nominal Power	0.5	(W)								
Max Power	1	(W)								
Mount Type	Flush									
Operating Temperature	-25 ~ +55	°C								
Storage Temperature	-25 ~ +55	°C								
Weight	38	(g)								
 DB UNLIMITED			Dynamic Speaker	Drawn by		Date	Checked by	Date	Approved by	Date
				A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
				SP770235-1						

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP770235-1](#)