



TOP VIEW

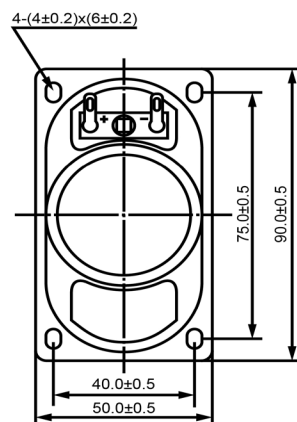

SIDE VIEW

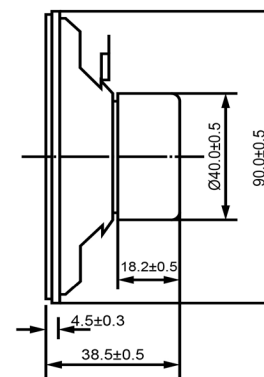

## Specifications

Description	Value	Unit
Shape	Rectangle	
Resonant Frequency	180	(Hz)
Frequency Range	180 ~ 16,000	(Hz)
SPL @ 10cm	85	(dBA)
Impedance	8	(Ohm)
Cone Material	Paper	
Nominal Power	3	(W)
Max Power	5	(W)
Mount Type	Frame	
Operating Temperature	-25 ~ +55	°C
Storage Temperature	-25 ~ +55	°C
Weight	172	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Dynamic Speaker

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
					</

SP900108-1

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP900108-1](#)