



TOP VIEW

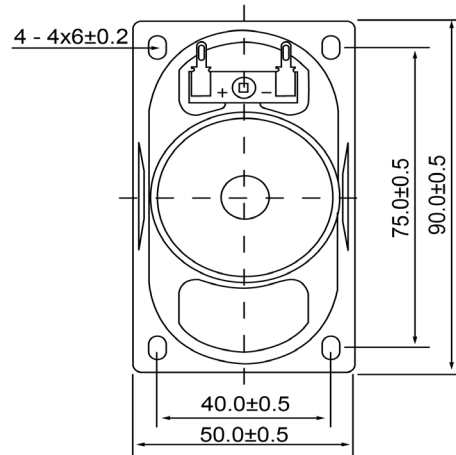

SIDE VIEW

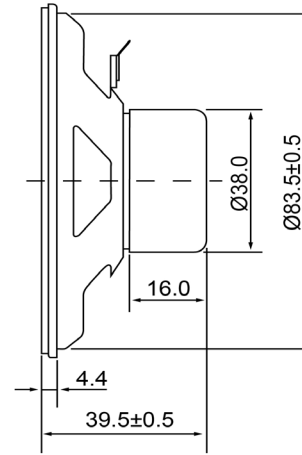

Specifications

Description	Value	Unit
Shape	Rectangle	
Resonant Frequency	220	(Hz)
Frequency Range	220 ~ 20,000	(Hz)
SPL @ 10cm	103	(dBA)
Impedance	4	(Ohm)
Cone Material	Paper	
Nominal Power	5	(W)
Max Power	10	(W)
Mount Type	Frame Mount	
Operating Temperature	-25 ~ +55	°C
Storage Temperature	-25 ~ +55	°C
Weight	127	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description			Date	Approved
1	Released from Engineering			2/5/2014	J.S.

Dynamic Speaker

SP900204-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP900204-1](#)