




SIDE VIEW

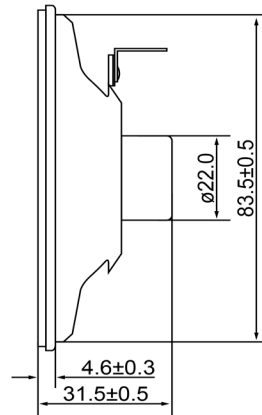

BOTTOM VIEW

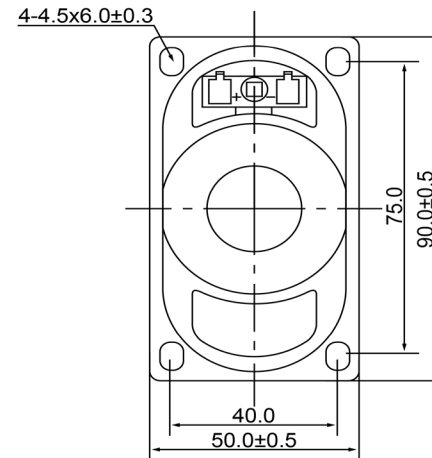

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Shape	Rectangle		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	200	(Hz)								
Frequency Range	200 ~ 20,000	(Hz)								
SPL @ 10cm	80	(dBA)								
Impedance	16	(Ohm)								
Cone Material	Paper									
Nominal Power	3	(W)								
Max Power	5	(W)								
Mount Type	Frame									
Operating Temperature	-20 ~ +55	°C								
Storage Temperature	-20 ~ +55	°C								
Weight	57	(g)								
 DB UNLIMITED				Drawn by		Date	Checked by	Date	Approved by	Date
				A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			Dynamic Speaker			SP900216-1				

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SP900216-1](#)