





DB UNLIMITED

Part Number:	1	
	DRAWN	11/21/2016
	CJ	
Description:	CHECKED	11/21/2016
	P.D.	
	APPROVED	11/21/2016
J.S.		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

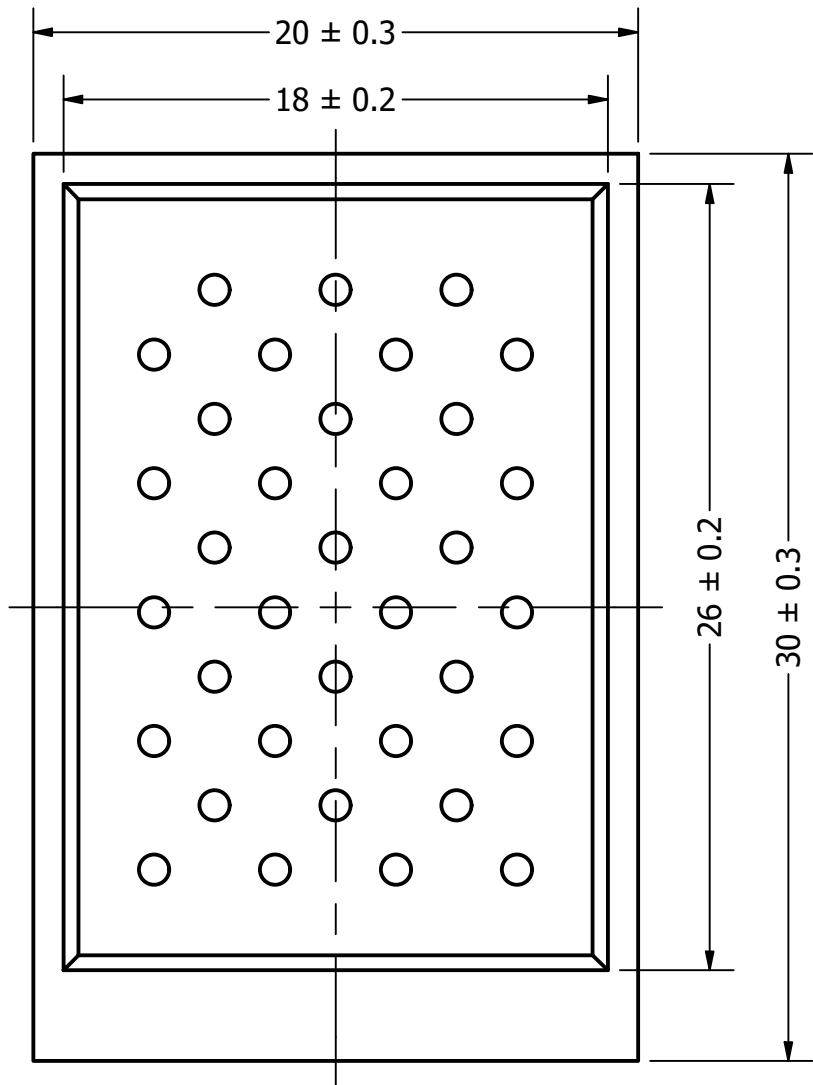

Side View

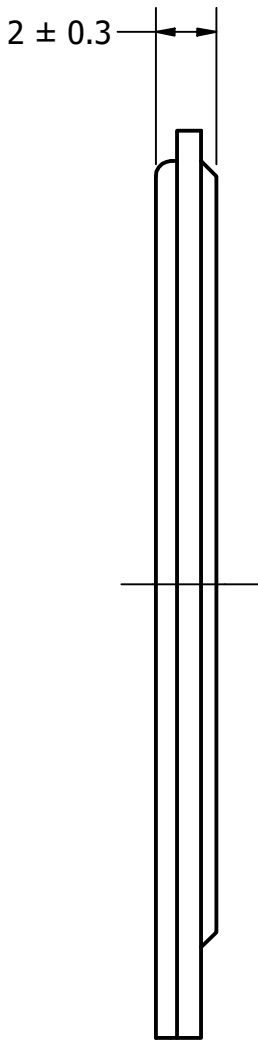

Bottom View

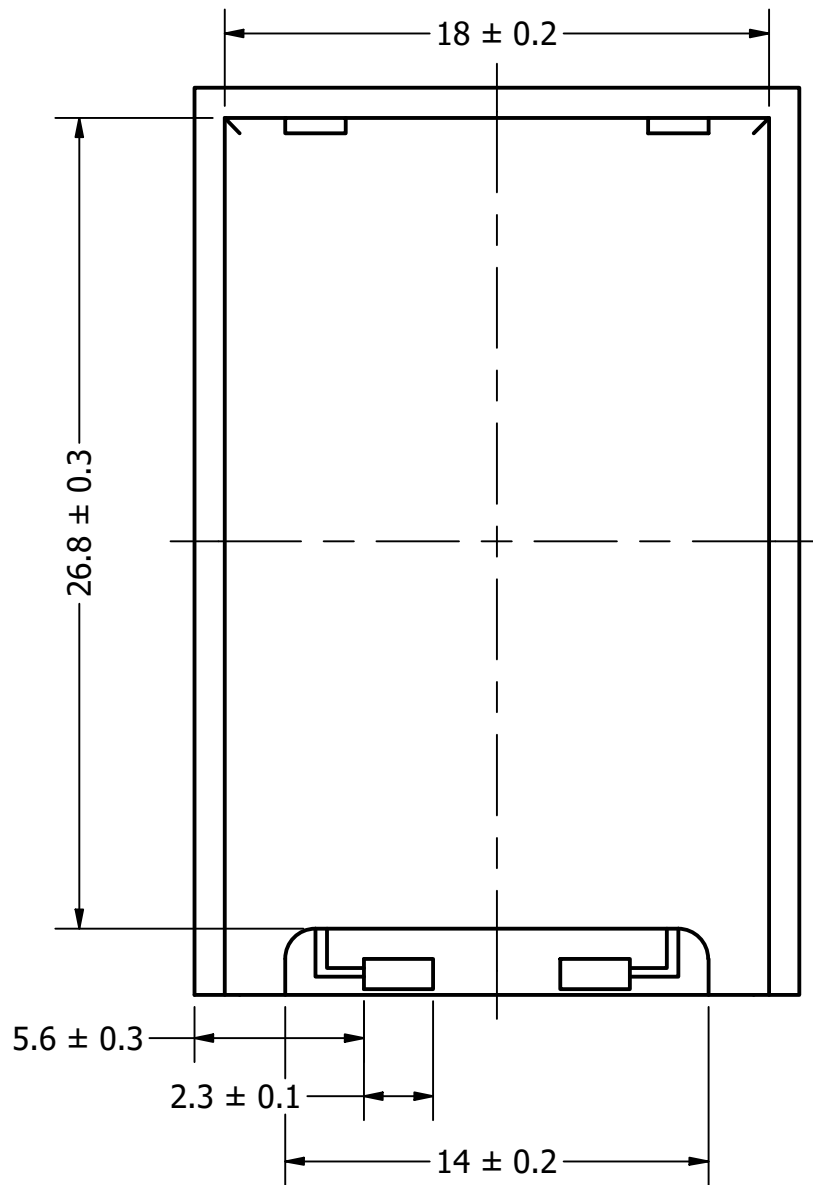

Items	Specifications	Conditions	REVISION HISTORY			
Sound Pressure Level	80	dB (@ 10cm)	REV	DESCRIPTION	DATE	APPROVED
Resonant Frequency	1,300	Hz		Released from Engineering	11/1/2013	J.S.
Frequency Range	300 ~ 20,000	Hz	1	Updated to new template	11/21/2016	J.S.
Rated Voltage	5	V	2	Updated frequency, capacitance, drawing, weight	2/19/2019	C.E.
Max. Voltage	16	V	3	Updated bottom view	8/17/2021	L.L.
Capacitance	1,300	nF				
Material	Stainless Steel		NOTES			
Mount Type	Flush Mount		1) All dimensions are in mm unless otherwise noted			
Storage Temperature	-30 ~ +85	°C	2) All tolerances are ± 0.5 mm unless otherwise noted			
Operating Temperature	-20 ~ +70	°C	3) All parts meet RoHS			
Weight	2.5	g	4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SZ300812-1](#)