





DB UNLIMITED

Part Number: TE082305-1	DRAWN CJ	7/13/2015
	CHECKED P.D	11/23/2015
	APPROVED J.S	11/23/2015
Description: Electro-Mechanical Transducer		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Bottom View

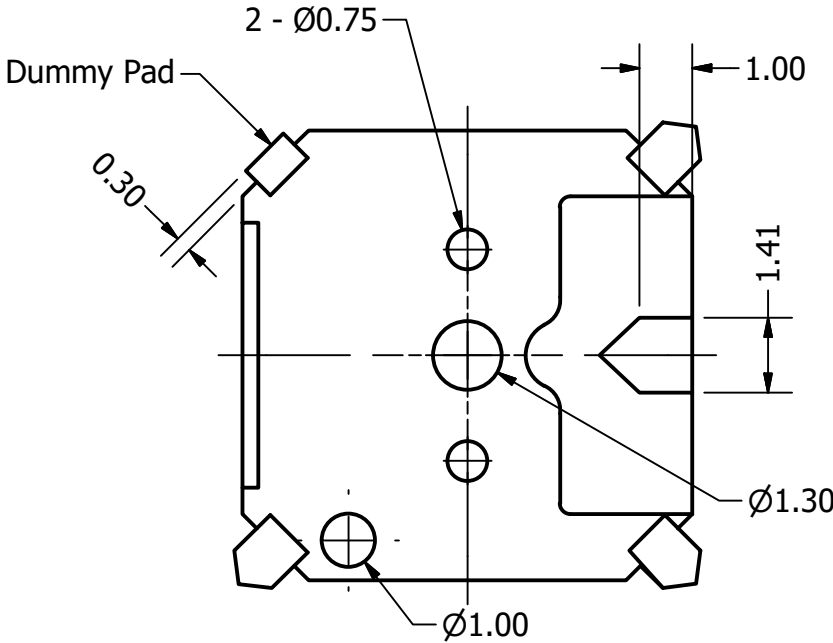


Side View (2)

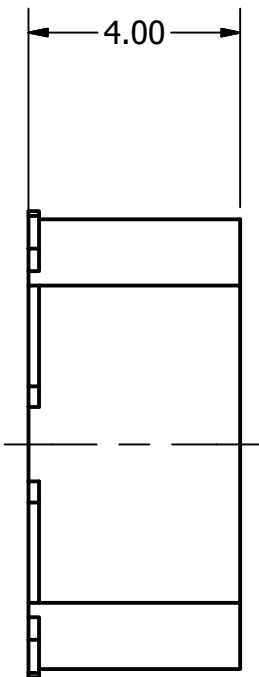

Top View

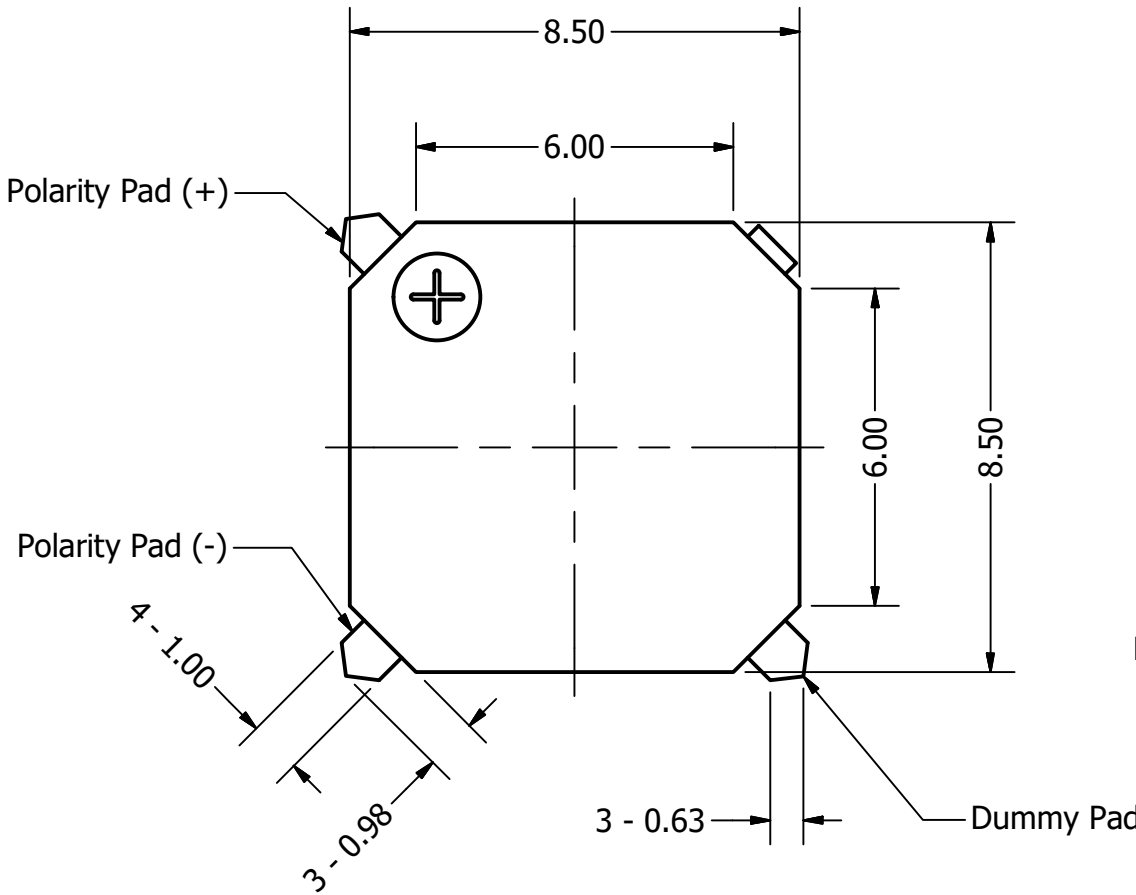

Side View (1)

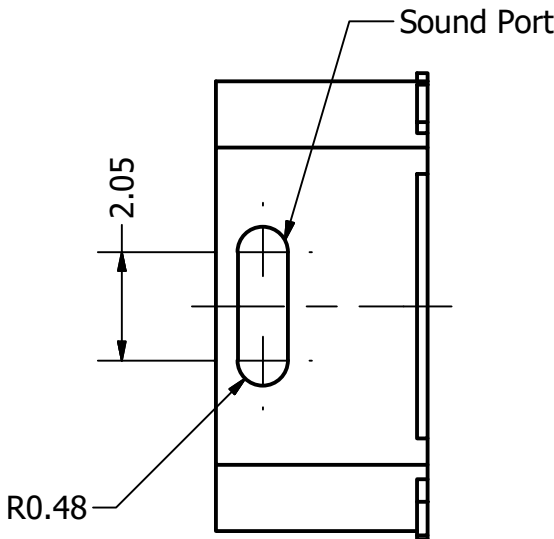

Items	Specifications	Conditions				
Sound Pressure Level	87	dB (@ 10cm)				
Resonant Frequency	2,350	Hz				
Rated Voltage	5	V				
Voltage Range	3~7	V				
Coil Resistance	30	ohm				
Max. Rated Current	90	mA				
Storage Temperature	-30 ~ +70	°C				
Operating Temperature	-30 ~ +70	°C				
Connection Method	Surface Mount Pads					
Mount Type	Surface Mount					
Housing Material	LCP					
Weight	0.6	g				
			REVISION HISTORY			
			REV	DESCRIPTION	DATE	APPROVED
				Released from Engineering	10/21/2013	J.S.
			1	Updated to new template	11/23/2015	J.S.
			NOTES			
			1) All dimensions are in mm unless otherwise noted			
			2) All tolerances are ± 0.5 mm unless otherwise noted			
			3) All parts meet RoHS			
			4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TE082305-1](#)