




TOP VIEW

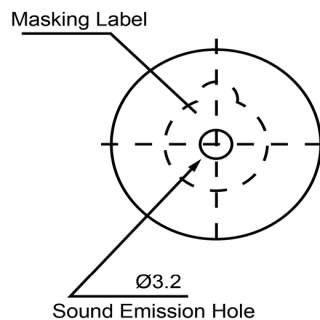

SIDE VIEW

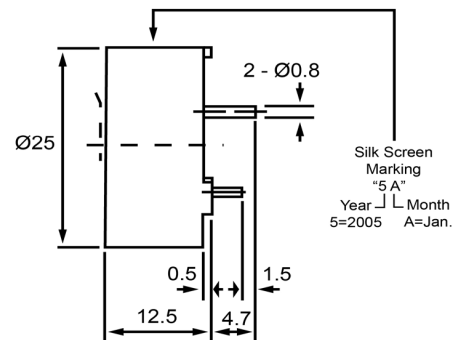

BOTTOM VIEW

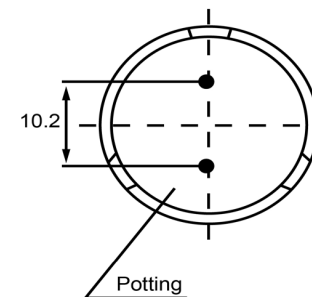

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description			Date	Approved	
Technology	Electro-Mechanical		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering			10/21/2013	J.S	
Resonant Frequency	730	(Hz)								
Rated Voltage	5	(V)								
SPL @ 10cm	85	(dBA)								
Coil Resistance	27	(ohm)								
Mount Type	Thru-hole									
Voltage Range	3 ~ 5	(V)								
Max Rated Current	80	(mA)								
Housing Material	NORYL									
Operating Temperature	-40 ~ +85	°C								
Storage Temperature	-40 ~ +85	°C								
Weight	10	(g)								
 DB UNLIMITED			Electro-Mechanical Transducer			TE250705-1				
			Drawn by			Date	Checked by	Date	Approved by	Date
			A.B.			10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TE250705-1](#)