





DB UNLIMITED

Part Number:	TP094003-1	DRAWN CJ	12/19/2016
		CHECKED P.D.	12/19/2016
Description:	Piezo Transducer	APPROVED J.S.	12/19/2016
		This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com	


Top View

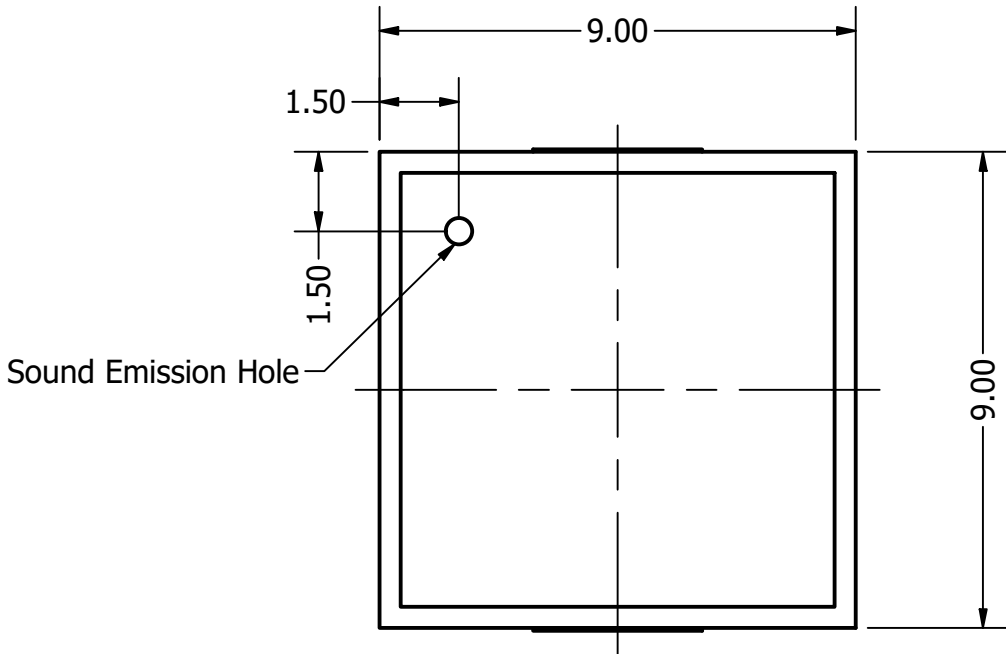

Side View

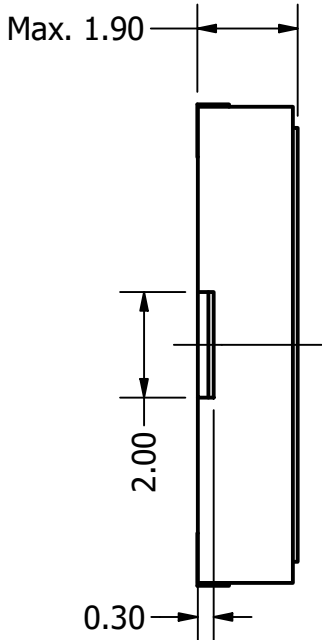

Bottom View

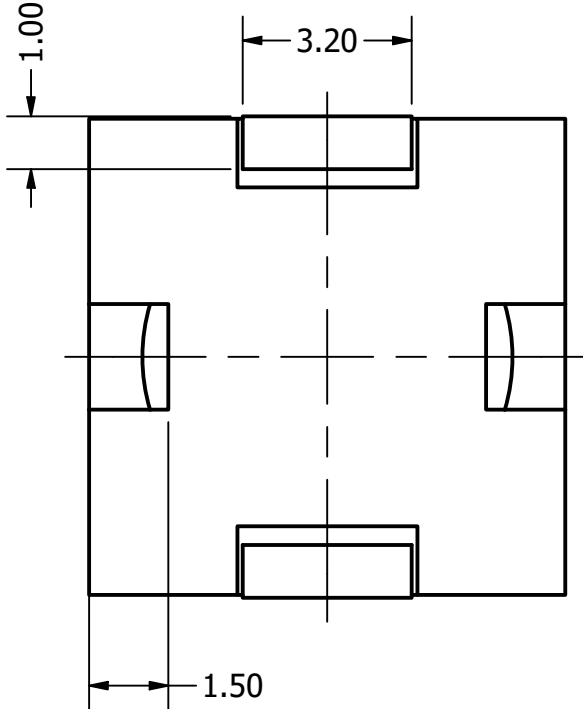

Items	Specifications	Conditions				
Sound Pressure Level	70	dB (@ 10cm)				
Resonant Frequency	4,000	Hz				
Rated Voltage	3	V				
Voltage Range	1 ~ 25	V				
Capacitance	12,000	pF				
Max. Rated Current	3	mA				
Storage Temperature	-40 ~ +85	°C				
Operating Temperature	-40 ~ +85	°C				
Connection Method	Surface Pads					
Mount Type	Surface Mount					
Housing Material	LCP					
Weight	0.2	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	3/31/2014	J.S.
1	Updated to new template	12/19/2016	J.S.
2	Updated specs and sound emission hole description	4/2/2020	J.S.

NOTES			
1) All dimensions are in mm unless otherwise noted			
2) All tolerances are ± 0.5 mm unless otherwise noted			
3) All parts meet RoHS			
4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP094003-1](#)