




DB UNLIMITED

Part Number:	DRAWN	6/10/2021
	CJ	
	CHECKED	6/10/2021
Description:	P.D.	6/10/2021
	APPROVED	
	J.S.	6/10/2021
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


TP103210-1

Piezo Transducer


Top View

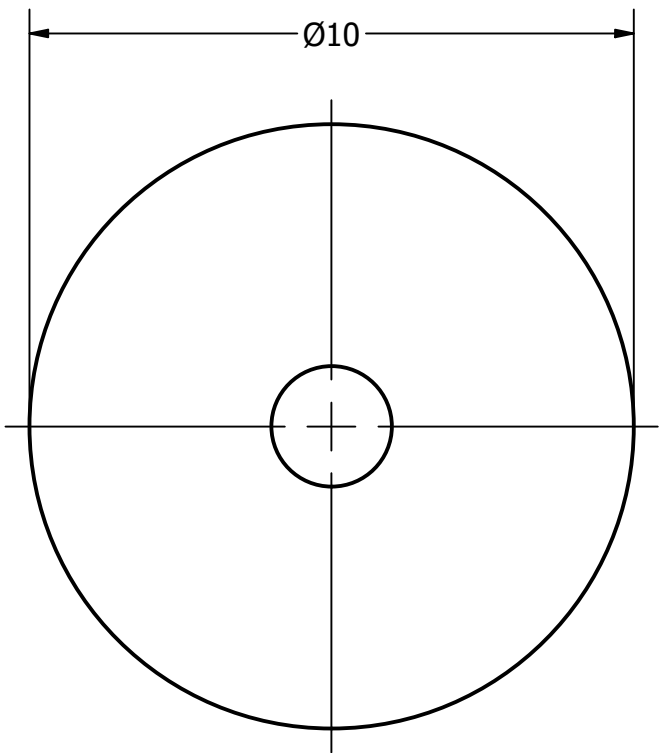

Side View

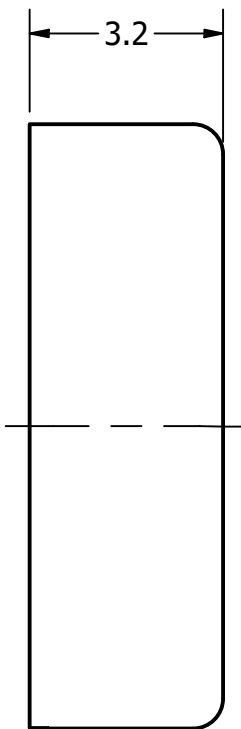

Bottom View

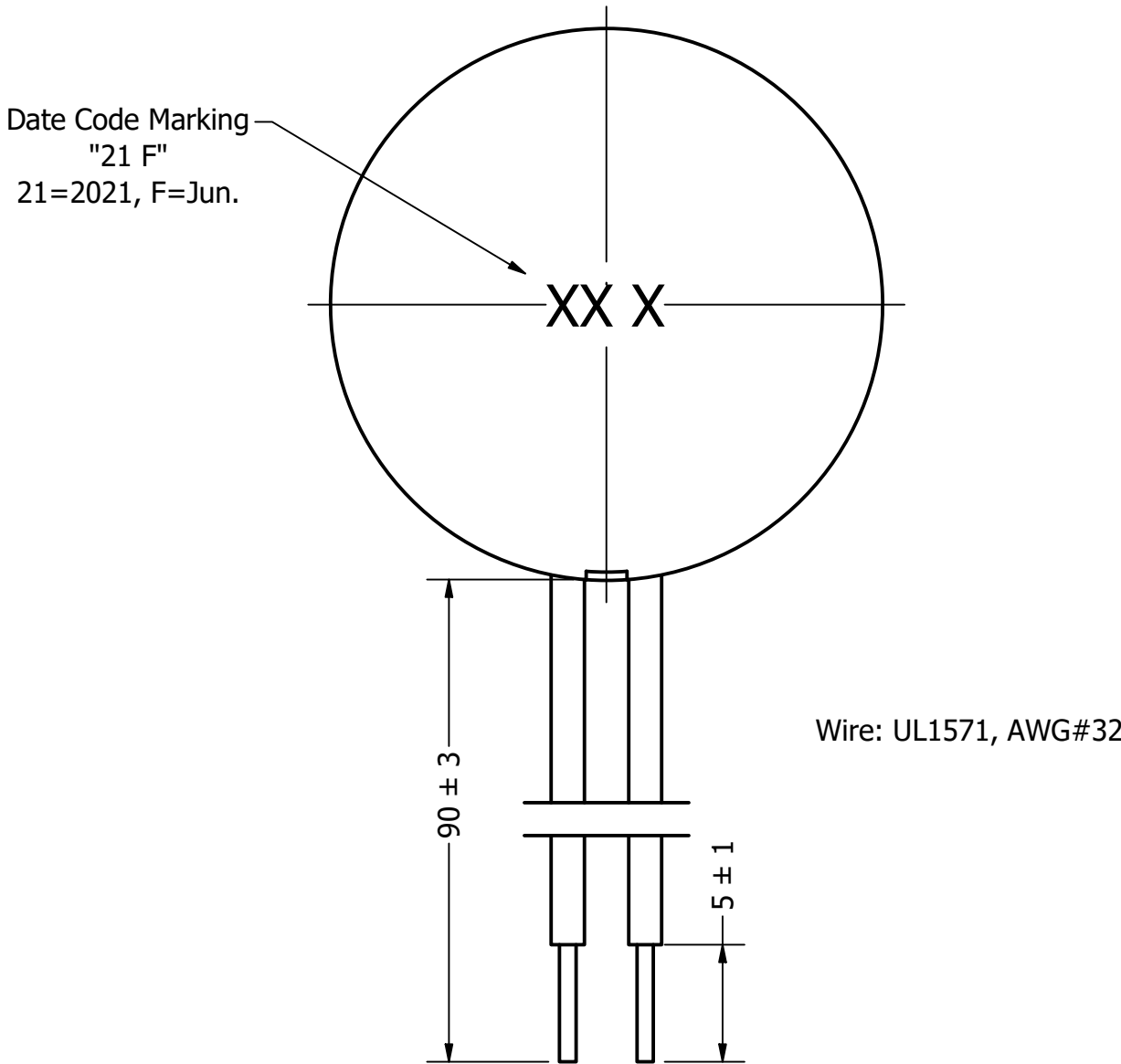

Items	Specifications	Conditions				
Min. Sound Pressure Level	80	dB (@ 10cm)				
Resonant Frequency	3,200	Hz				
Rated Voltage	10	V				
Voltage Range	1 ~ 30	V				
Capacitance	11,000	pF				
Max. Rated Current	7	mA				
Storage Temperature	-20 ~ +70	°C				
Operating Temperature	-20 ~ +60	°C				
Connection Method	Lead Wires					
Mount Type	Flush Mount					
Housing Material	ABS					
Weight	1	g				
			REVISION HISTORY			
			REV	DESCRIPTION	DATE	APPROVED
			1	Released from Engineering	10/21/2013	J.S.
				Updated to new template	6/10/2021	J.S.
			NOTES			
			1) All dimensions are in mm unless otherwise noted			
			2) All tolerances are ± 0.5 mm unless otherwise noted			
			3) All parts meet RoHS			
			4) Subject to change or redrawn without notice			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP103210-1](#)