




TOP VIEW

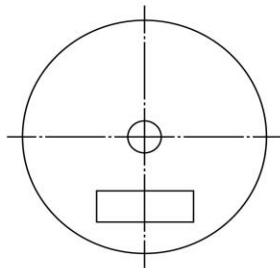


SIDE VIEW

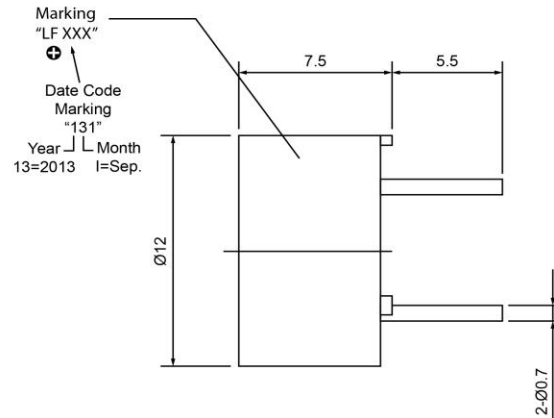

BOTTOM VIEW

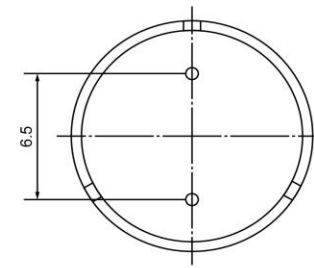

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		5/18/2015	J.S.		
Resonant Frequency	4,500	(Hz)								
Rated Voltage	12	(V)								
SPL @ 10cm	80	(dBA)								
Capacitance	10,000	(pF)								
Mount Type	Thru-hole									
Voltage Range	1 ~ 30	(V)								
Max Rated Current	5	(mA)								
Housing Material	MPPO									
Operating Temperature	-30 ~ +70	°C								
Storage Temperature	-40 ~ +85	°C	<div> DB UNLIMITED</div>	Drawn by		Date	Checked by	Date	Approved by	Date
Weight	2	(g)		G.W.		5/6/2015	C.S.	5/6/2015	J.S.	5/18/2015
				Piezo Transducer			TP124512-1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP124512-1](#)