




TOP VIEW

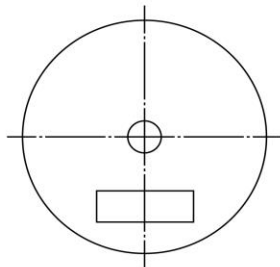


SIDE VIEW

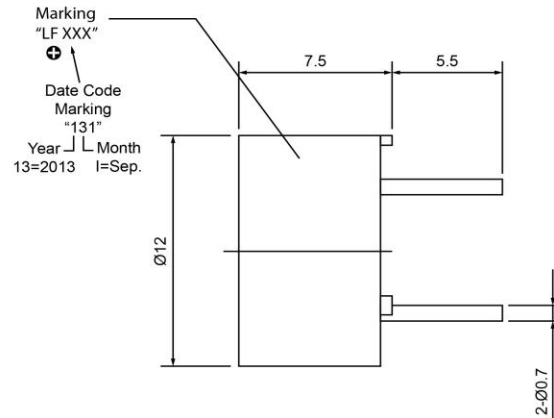

BOTTOM VIEW

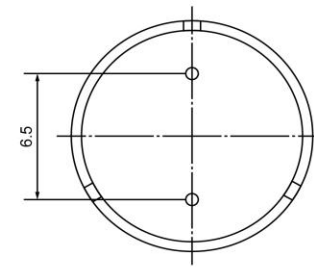

Specifications			Notes	Revision History							
Description	Value	Unit		Version	Description		Date		Approved		
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		5/18/2015		J.S.		
Resonant Frequency	4,500	(Hz)									
Rated Voltage	12	(V)									
SPL @ 10cm	80	(dBA)									
Capacitance	10,000	(pF)									
Mount Type	Thru-hole										
Voltage Range	1 ~ 30	(V)									
Max Rated Current	5	(mA)									
Housing Material	MPPO										
Operating Temperature	-30 ~ +70	°C									
Storage Temperature	-40 ~ +85	°C	 DB UNLIMITED	Drawn by		Date	Checked by	Date	Approved by	Date	
Weight	2	(g)		G.W.		5/6/2015	C.S.	5/6/2015	J.S.	5/18/2015	
				Piezo Transducer				TP124512-1			

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP124512-1](#)