





DB UNLIMITED

Part Number:	DRAWN	10/7/2016
	CJ	
	CHECKED	10/7/2016
Description:	P.D.	
	APPROVED	10/7/2016
Piezo Transducer		J.S.
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>		


Top View

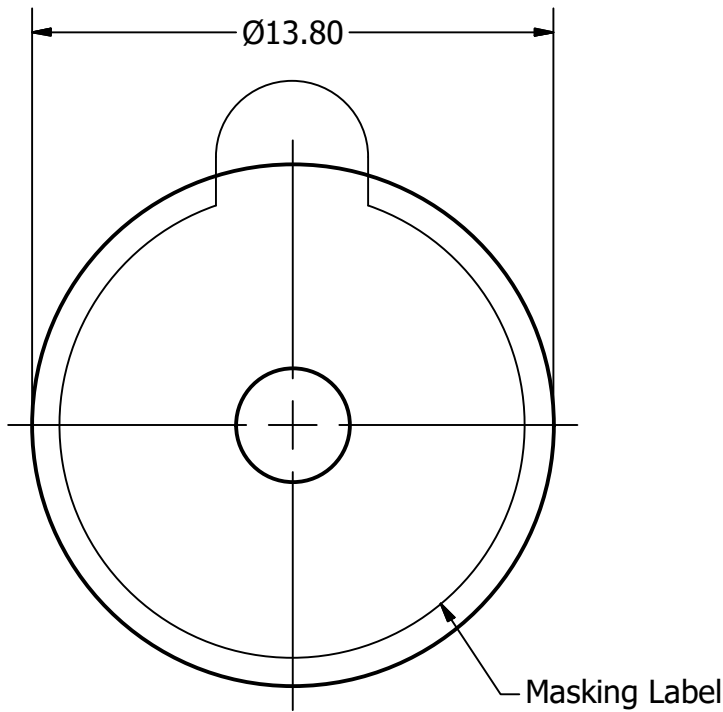

Side View

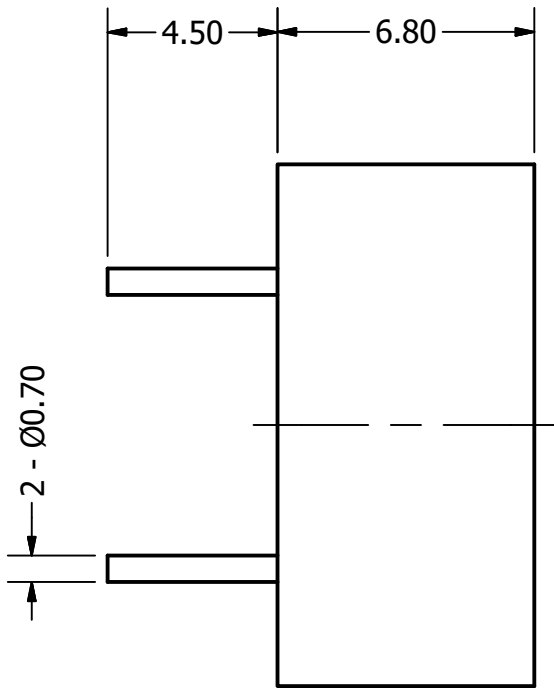

Bottom View

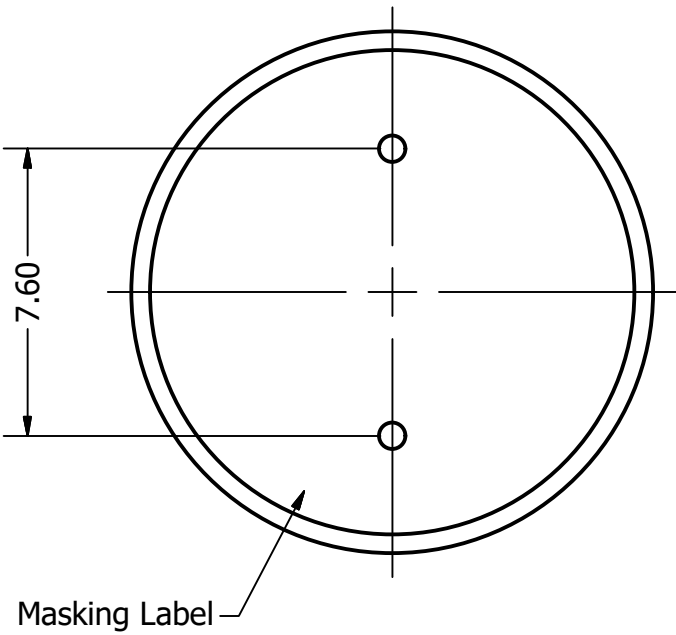

Items	Specifications	Conditions				
Sound Pressure Level	80	dB (@ 10cm)				
Resonant Frequency	4,000	Hz				
Rated Voltage	5	V				
Voltage Range	1 ~ 20	V				
Capacitance	13,000	pF				
Max. Rated Current	1	mA				
Storage Temperature	-30 ~ +80	°C				
Operating Temperature	-20 ~ +70	°C				
Connection Method	PC Pins					
Mount Type	Thru Hole					
Housing Material	Noryl					
Weight	1	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	10/21/2013	J.S.
1	Updated to new template	10/7/2016	J.S.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP134005-1](#)