




TOP VIEW

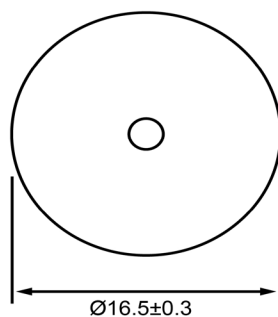

SIDE VIEW

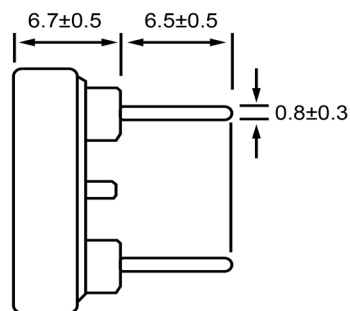

BOTTOM VIEW

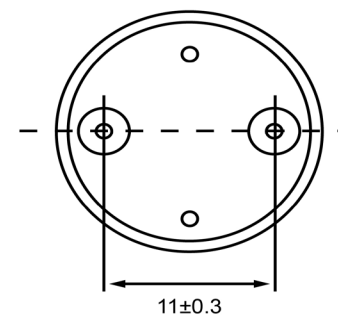

## Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	4,000	(Hz)
Rated Voltage	3	(V)
SPL @ 10cm	75	(dBA)
Capacitance	10,000	(pF)
Mount Type	Thru Hole	
Voltage Range	1 ~ 25	(V)
Max Rated Current	5	(mA)
Housing Material	NORYL	
Operating Temperature	-20 ~ +60	°C
Storage Temperature	-20 ~ +60	°C
Weight	5	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted  
 2) All parts meet RoHS



DB UNLIMITED

Piezo Transducer

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

TP164003-2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP164003-2](#)